

Imperial joint kit, NBR90Sh A

BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

Applications

- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for use in the maintenance dept

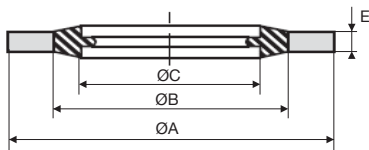

Box contents

Quantity	For thread	A ^{+0,13} ₀	B ^{+/-0,13}	C ^{+/-0,13}	E ^{+/-0,15}
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm

Our other products



T5-BAR

T type tooth bar
stock, T5



PR820

Idler sprocket for slat
top chain, Rangs 820
and 815



CHA35

Hinge for aluminium
profile, Hinge



ACLLPP

Latch for aluminium
profile, Spring
operated latch



HTD14M_55

HTD Heavy duty
timing pulley, HTD14
Cast



BLHB30

Right angled gearbox,
bored shafts, up to
4.47 Nm



D-PAR_SS

Stainless steel elasto
mount, stainless steel



CHMR30

Worm and wheel gear
reducer, up to 28 Nm



VBFP

Small 6 lobe threaded
handle - female,



SLB

Indexing plunger,
stainless steel



DOMI50

Accessories, Plate



GLT3-46A

Telescopic drawer
with damper,

Complementary products



BOX-TOR-TOOL

Box set of tool for
Nitrile O-rings,
Extraction tools