

# Imperial joint kit, NBR90Sh A

## BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:  
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

### Applications

- Suitable for:
- Hydraulic fluids
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for use in the maintenance dept

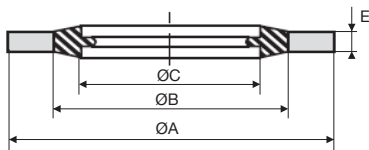

### Box contents

Quantity	For thread	A <sup>+0,13</sup> <sub>0</sub>	B <sup>+/-0,13</sup>	C <sup>+/-0,13</sup>	E <sup>+/-0,15</sup>
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm

## Our other products



EHD16

Internal epicyclic servo reducers, from 210 to 380 Nm



VRM

Female swivelling lifting rings, Female swivelling



PO

Pull handle - Multi-sector, Tapped recessed insert



PDD

Actuating plunger, Non-rotating detector shaft



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts



MDB\_MTB

Moulded plastic bevel gear (nylon), 2:1



CHV

Mechanical speed variator, from 0,18 to 1,5kW



MEB

Moulded plastic bevel gear (nylon), 1:1



HSE-HSB

Hexagonal spacer, Brass




ACL-PL

Joining plate for aluminium profile, Joint plate - 86x86



CAP815

Slim slat top chain stainless steel, Narrow range 815

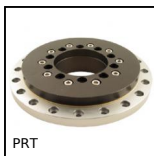

PRT

Rotary table iglidur®, Iglidur®, aluminium and stainless steel

## Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools