

Imperial joint kit, NBR90Sh A

BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

Applications

- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for use in the maintenance dept

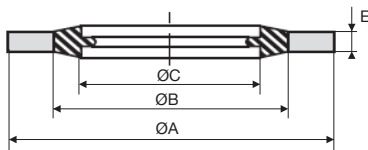

Box contents

Quantity	For thread	A ^{+0,13} ₀	B ^{+/-0,13}	C ^{+/-0,13}	E ^{+/-0,15}
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm


Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 3:1



 HLA28
Right angle spiro bevel gearbox, Up to 182Nm



GPLso
Brush, silk



HCA
Magnetic screw with socket, Steel



CHA_GC_14SS
Stainless steel garnet hinge, To screw



GE1006
Elastic ringed latch, Hooks into a slot




PTA150
Articulated levelling foot, pressed base Ø150, Ø 150



DER71
Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



 BLHB60
Right angled gearbox, bored shafts, up to 70 Nm



RPPM
RPP type belt per metre, RPP8 Steel cored polyurethane



CHAPAM
Weld-on hinge with flat end, Steel



WING
Manually tightened wing nut, Steel (ANSI B18-17)

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools