

Imperial joint kit, NBR90Sh A

BOX-TOR-INCH For fasteners and fittings

- Selection of BS imperial sizes
- 7 sizes
- Material:
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C


Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for use in the maintenance dept

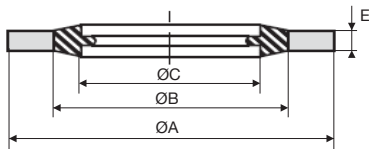

Box contents

Quantity	For thread	A ^{+0.13} ₀	B ^{+/-0.13}	C ^{+/-0.13}	E ^{+/-0.15}
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm

Our other products



Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



Storage bin, 8mm



Chain tool, Drive
chain maintenance
tools



T type timing belt per
metre, T5 Steel cored
polyurethane



Cap nut Hygienic
Design®, Compact



Brush, silk



Right angle helical
reducers, from 4.50 to
62 Nm



Magnetic screw with
socket, Steel



Rotex®, jaw coupling,
steel



Cylindrical sintered
ferrous bush, Self-
lubricating FP20



Dynamic washer
DIN2093, Steel



Right angle helical
reducers, from 0.40 to
2.53 Nm

Complementary products



Box set of tool for
Nitrile O-rings,
Extraction tools