

Nitrile O-ring kit


BOX-TOR-MAX Sizes from 2.9x1.78mm to 82.14x3.53mm

- 5 different boxes containing AS/BS standards in
- 78 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

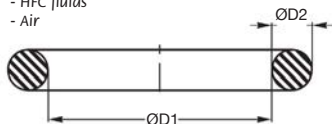

Kit contents:

Box 1:30 O-rings in 5 sizes

Quantity	ØD1	ØD2
8	24,99	3,53
8	32,92	3,53
6	37,69	3,53
4	47,22	3,53
4	56,74	3,53

Box 2:127 O-rings for BOSS fittings in 6 sizes

Quantité	ØD1	ØD2
25	8,92	1,83
25	11,89	1,98
25	16,36	2,21
25	19,18	2,46
16	23,47	2,95
11	29,74	2,95

Box 3:485 1.78mm O-rings in 24 sizes

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
25	2,90	1,78	25	18,77	1,78
25	3,68	1,78	20	20,35	1,78
25	4,47	1,78	20	21,95	1,78
25	5,28	1,78	20	23,52	1,78
25	6,07	1,78	15	25,12	1,78
25	7,65	1,78	15	26,70	1,78
25	9,25	1,78	15	28,30	1,78
25	10,82	1,78	15	29,87	1,78
25	12,42	1,78	15	31,47	1,78
25	14,00	1,78	15	34,65	1,78
25	15,60	1,78	10	37,82	1,78
25	17,17	1,78	10	41,00	1,78

Dimensions en mm

BOX-TOR-MAX



Box 4:440 2.62mm

O-rings in 24 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
25	7,59	2,62	15	26,64	2,62
25	9,19	2,62	15	28,24	2,62
25	10,77	2,62	15	29,82	2,62
25	12,37	2,62	15	31,42	2,62
25	13,94	2,62	15	32,99	2,62
25	15,54	2,62	15	34,59	2,62
25	17,12	2,62	15	36,17	2,62
25	18,72	2,62	10	37,77	2,62
25	20,30	2,62	10	39,34	2,62
25	21,89	2,62	10	42,52	2,62
20	23,47	2,62	10	45,69	2,62
20	25,07	2,62	5	48,90	2,62

Box 5:285 3.53mm

O-rings in 19 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
20	18,64	3,53	14	34,52	3,53
20	20,22	3,53	14	36,09	3,53
20	21,82	3,53	13	37,69	3,53
20	23,39	3,53	12	40,87	3,53
20	24,99	3,53	12	44,04	3,53
16	26,57	3,53	10	50,39	3,53
16	28,17	3,53	10	56,74	3,53
16	29,74	3,53	10	69,44	3,53
16	31,34	3,53	10	82,14	3,53
16	32,92	3,53			



DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-MAX	NBR 90 Sh A	1415 pièces	1 to 2 197,33 €

Dimensions mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

219

Our other products



FBL4004_K32
Brush strip per metre,
Black striated
polypropylene (PP)



ZDB
Machined plastic
bevel gear , 2:1



MSP3815
Masterplate®
glueable insert
rectangular,
rectangular with nut



RIMple
Locking castor, with
mounting plate



GMK17_BROSSE
Brush strip, Cone-
shaped - brush



LF
Precision locknut,
Precision locknut



BLHM50
Right angled gearbox,
double output shafts,
up to 30 Nm



MCL
Cylindrical threaded
sleeve, Cylindrical -
stainless steel



ZG1
Plastic spur gear,
Machined plastic
(delrin)



SH1
Parallel axis helical
gear, Machined plastic
(delrin)



BWU
Compact precision
slide, from 1510 N to
10500 N



TPEpbd
Castor for aluminium
profile, Swivel with
brake

Complementary products