

Nitrile O-ring kit


BOX-TOR-MAX Sizes from 2.9x1.78mm to 82.14x3.53mm

- 5 different boxes containing AS/BS standards in
- 78 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

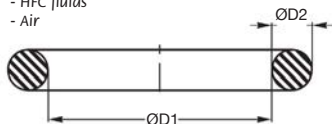

Kit contents:

Box 1:30 O-rings in 5 sizes

Quantity	ØD1	ØD2
8	24,99	3,53
8	32,92	3,53
6	37,69	3,53
4	47,22	3,53
4	56,74	3,53

Box 2:127 O-rings for BOSS fittings in 6 sizes

Quantité	ØD1	ØD2
25	8,92	1,83
25	11,89	1,98
25	16,36	2,21
25	19,18	2,46
16	23,47	2,95
11	29,74	2,95

Box 3:485 1.78mm O-rings in 24 sizes

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
25	2,90	1,78	25	18,77	1,78
25	3,68	1,78	20	20,35	1,78
25	4,47	1,78	20	21,95	1,78
25	5,28	1,78	20	23,52	1,78
25	6,07	1,78	15	25,12	1,78
25	7,65	1,78	15	26,70	1,78
25	9,25	1,78	15	28,30	1,78
25	10,82	1,78	15	29,87	1,78
25	12,42	1,78	15	31,47	1,78
25	14,00	1,78	15	34,65	1,78
25	15,60	1,78	10	37,82	1,78
25	17,17	1,78	10	41,00	1,78

Dimensions en mm

BOX-TOR-MAX



Box 4:440 2.62mm

O-rings in 24 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
25	7,59	2,62	15	26,64	2,62
25	9,19	2,62	15	28,24	2,62
25	10,77	2,62	15	29,82	2,62
25	12,37	2,62	15	31,42	2,62
25	13,94	2,62	15	32,99	2,62
25	15,54	2,62	15	34,59	2,62
25	17,12	2,62	15	36,17	2,62
25	18,72	2,62	10	37,77	2,62
25	20,30	2,62	10	39,34	2,62
25	21,89	2,62	10	42,52	2,62
20	23,47	2,62	10	45,69	2,62
20	25,07	2,62	5	48,90	2,62

Box 5:285 3.53mm

O-rings in 19 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
20	18,64	3,53	14	34,52	3,53
20	20,22	3,53	14	36,09	3,53
20	21,82	3,53	13	37,69	3,53
20	23,39	3,53	12	40,87	3,53
20	24,99	3,53	12	44,04	3,53
16	26,57	3,53	10	50,39	3,53
16	28,17	3,53	10	56,74	3,53
16	29,74	3,53	10	69,44	3,53
16	31,34	3,53	10	82,14	3,53
16	32,92	3,53			



DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-MAX	NBR 90 Sh A	1415 pièces	1 to 2 197,33 €

Dimensions mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

219

Our other products



VB

Small 6 lobe threaded handle - female, Duroplast - Stainless steel



TCXR

Automatic chain tensioner, With stainless steel sprocket



RTN

BoWex® curved tooth gear coupling, Nylon



BAG-MI

Split shaft collar with clamp lever, Steel



SNG

Stainless/Polymer pillow block bearing, Cast iron - Split pillow



PSG15

Spur gear - precision range, Case hardened steel 20NCD2



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



BPVM

Miniature ball transfer unit, Miniature to screw



EAR

Bearing locknut, Self locking locknut - nylon



DIA

Ring operated locking bolt, with ring



PCLA_M

Technopolymer clamping lever -



AC156-157

Strike for toggle latch, 25.5mm

Complementary products