

# O-Ring kit, NBR90Sh A

## BOX-TOR-ORFSizes from 7.65x 1.78mm to 37.82x1.78mm

- Selection of O-Rings for ORF fittings
- 8 sizes
- Material:  
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C


### Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

### Info

- Ideal for use in the maintenance dept.

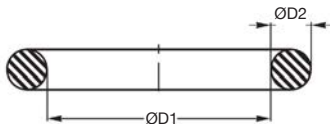

### Box contents

Quantity	ØD1	ØD2
25	7,65	1,78
25	9,25	1,78
25	12,42	1,78
25	15,60	1,78
20	18,77	1,78
15	23,52	1,78
10	29,87	1,78
10	37,82	1,78

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-ORFS	NBR 90 Sh A	155 pieces	35,77 €

All dimensions in mm

## Our other products



Speed controller 5A accessories, Kit of 4 cables for DC motor



Spur gear - precision range, Stainless steel 303



Brush strip per meter horsehair fibres Ø0.2, Black horsehair



Strike for toggle latch, 25.5mm



Arm with folding rotating handle,



Articulated fixable foot with pressed base Ø80, Ø 80



Flexible slat top chain acetal, Large range 882



Nut for aluminium profile, Stainless steel square nut with tab



Multifunction display, Mounting bracket for



Igalbal® pillow block bearing, Polymer



Hypoid gearbox - Stainless steel, up to



Male rod ends , Stainless steel / PTFE

## Complementary products



Box set of tool for Nitrile O-rings, Extraction tools