

# Boxed set of wide threaded self tapping inserts

For wood

BOX-INS-W

- Selection of self tapping inserts with a large external thread for use in wood
- Assembles by deformation, no special tools required
- With hexagonal socket for assembly
- Material:  
White galvanized steel

## Applications

- Can be used in soft plastics or woods and rubber



480 pieces




010

440

002

006

Quantity	Type	ØD	L	Ød	SW
50	010	10	12	M5	5
50	010	12	15	M6	6
30	010	14	15	M8	8
50	440	10	12	M5	5
50	440	12	12	M6	6
30	440	14	15	M8	8
50	002	10	10	M5	-
50	002	12	15	M6	-
30	002	14	14	M8	-
30	006	8	12	M5	-
30	006	15	15	M6	-
30	006	12	15	M8	-

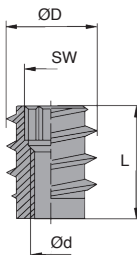

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Price each
BOX-INS-W	480 pieces	373,29 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019


205

## Our other products




SH1

 Parallel axis helical gear, Steel 20NCD2



RIMtce

 Locking castor, with central hole



RPP14

RPP heavy duty timing belt, RPP14



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



HDSS

Needle roller double universal joint - Stainless steel, Heavy duty



CHT

Asynchronous AC Motor, 0.18 to 0.55kW



ACM\_AZ

Mounting bracket for bonnet fastener, Hook



ACLEPP

Right angled bracket for aluminium profile, 2 holes



UTKpwr

Utilitak® V rail, V rail



SRP

Slotted spring pin ISO8752, Split ISO



SVG

Adjustable latch clamp with strike



BSPM

Miniature ballscrew, Nut+rolled ballscrew

## Complementary products



INS100

Self tapping inserts-coarse thread, Coarse thread



INS150

Self tapping insert with collar-coarse thread, With collar-coarse t...



BOXINS300

Box set of self tapping inserts, Boxed set - For hard materials