

Box sets of self-locking nuts **DIN985**

BOX-NINA

Steel

- Boxes of standard DIN985 self-locking nuts

Application

- Ideal for the maintenance department
or for use in workshops



- Box details

Quantity	Thread ØM	Thread
Standard thread		
100	M4	0,70
100	M5	0,80
100	M6	1,00
50	M8	1,25
50	M10	1,50
25	M12	1,75
10	M14	2,00
10	M16	2,00
Fine thread		
50	M10	1,00
25	M12	1,50
20	M14	1,50
10	M16	1,50

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Quantity per box	Price each
BOX-NINA	550 washers	75,50 €

Our other products



CHA_GC_1455
Stainless steel garnet hinge, To screw



ZDB
Machined plastic bevel gear (delrin), 2:1




PDD
Spring operated plunger, Non-rotating detector shaft



BS3
Panamech, Multi-Beam, Stainless steel - with set screw



 DOMI80
DOMILINE - Accessories, Fixing kit



PRF_PSP_PR
Cover profile, Inserts into slot



SME
Rod end, Stainless steel / PTFE



CHTRP
Single and dual output gearboxes, Up to 9,1 Nm




EDS
Support component, 90° angle bracket



NCT
Square tube connector, Fixed angle



EKGS
Backlash free coupling Gerwah®, from 0.5 to 35Nm

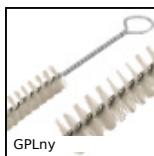

GPLny
Brush, nylon

Complementary products



NIN
Self locking nut - DIN 985, Steel



BOX-SHNA
Six-sided nut - DIN 934, Box set of steel nuts



BOX-WM
Washer - DIN 125, Box set of steel washers