

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

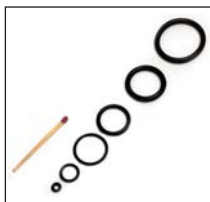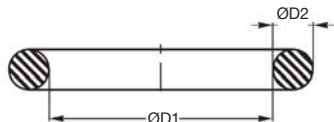

Box contents

Quantity	ØD1	ØD2
20	2,90	1,78
20	3,68	1,78
20	4,48	1,78
20	5,28	1,78
20	6,07	1,78
20	7,66	1,78
20	9,25	1,78
15	10,82	1,78
15	12,42	1,78
10	14,00	1,78

Quantity	ØD1	ØD2
10	15,60	1,78
5	17,16	1,78
5	18,77	1,78
15	9,19	2,62
15	10,78	2,62
15	12,37	2,62
15	13,95	2,62
10	15,54	2,62
10	17,13	2,62
10	18,72	2,62

Quantity	ØD1	ØD2
5	20,29	2,62
5	21,89	2,62
5	23,47	2,62
5	18,64	3,53
5	20,22	3,53
5	21,82	3,53
5	23,40	3,53
5	24,99	3,53
5	26,58	3,53
5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

Our other products



MAX26
Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm



CCL55
Stainless steel wire
thimble, Stainless
steel



ACLEPP
Right angled bracket
for aluminium profile,
8 holes



EHD08-3
Internal epicyclic
servo reducers, from
20 to 50 Nm



RFV63
Stainless steel worm
and wheel gearbox,
up to 152 Nm



PRF_RR
Coupling bar for
aluminium profile,
Coupling bar



ZH6
Plastic spur gear,
Machined plastic
(delrin)



AZY
Cylindrical elastomeric
mount, Steel



BSM
Spring plunger with
internal hexagonal
socket, steel body,



SBS_L
Chain link, Stainless
steel



AT10courroie
AT type timing belt,
AT10 Steel cored
polyurethane



AT5P_AT10P
Connecting plate for
AT type timing belts,
AT10

Complementary products



BOX-TOR-TOOL
Box set of tool for
Nitrile O-rings,
Extraction tools