

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

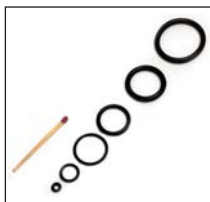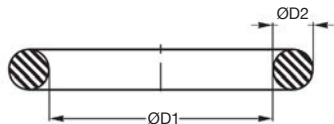

Box contents

Quantity	ØD1	ØD2
20	2,90	1,78
20	3,68	1,78
20	4,48	1,78
20	5,28	1,78
20	6,07	1,78
20	7,66	1,78
20	9,25	1,78
15	10,82	1,78
15	12,42	1,78
10	14,00	1,78

Quantity	ØD1	ØD2
10	15,60	1,78
5	17,16	1,78
5	18,77	1,78
15	9,19	2,62
15	10,78	2,62
15	12,37	2,62
15	13,95	2,62
10	15,54	2,62
10	17,13	2,62
10	18,72	2,62

Quantity	ØD1	ØD2
5	20,29	2,62
5	21,89	2,62
5	23,47	2,62
5	18,64	3,53
5	20,22	3,53
5	21,82	3,53
5	23,40	3,53
5	24,99	3,53
5	26,58	3,53
5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

Our other products



T5M T10M
T type timing belt per metre, T10 Steel cored polyurethane



SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



M1
Worm and wheel set, Bronze



LRX
Linear roller slide, Rail - from 9410 N to 101000 N



OP3_14_06
Reducing sleeve for OP indicators, Reduction socket



PRF_CLIP_45
Cable clip for aluminium profile, For cable chute



CLM
Male clevis end, Steel short



P30
Worm and wheel gear reducer, up to 8.80 Nm



OP9
Mechanical digital position indicator, 5 numbers



DOG111
Motor-gearbox 12V and 24V DC, from 1.5 to 6 Nm



PRES3HR
Manual workbench press, Force up to 400kg



CM_CO
Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...

Complementary products



BOX-TOR-TOOL
Box set of tool for Nitrile O-rings, Extraction tools