

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

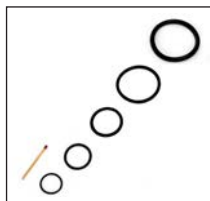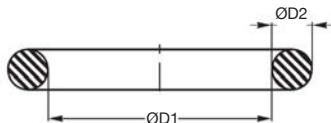

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

213

Our other products



GE1006
Flexible toggle latch,
Hooks into a slot



PM2
Worm, Machined
plastic (delrin)



HTD5M_09
HTD-type pulley for
RPP-type belt, HTD5
Aluminium



PRFPVER
Connecting/joining,
Vertical bearing
support




G-ECO
Spur gear, Steel C45



GPB
Threaded spherical
knob, Moulded thread



 GDR880
Straight guide,
Ranges 880 and 881



P15
Worm and wheel
gearbox, up to 3,75
Nm



ARTE
Flexible bush, For
multi-directional loads



SLH
Clamp, Horizontal
Lever Clamp - steel



HRV
V- rail guidance
system, Rail with
carriage



SHA_PT
Hand wheel,
Polyamide

Complementary products



BOX-TOR-TOOL
Box set of Nitrile O-
rings, Extraction tools