

Box set of Nitrile O-rings

BOX-TOR-C Diameters 3,00x1,50mm à 30,20x3,00mm



- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

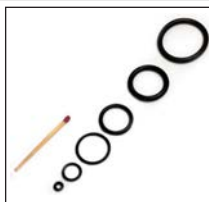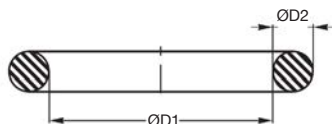

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	3,00	1,50	15	6,30	2,40	10	10,00	3,00
20	5,00	1,50	15	8,30	2,40	10	12,00	3,00
20	7,00	1,50	15	11,30	2,40	10	14,00	3,00
20	9,00	1,50	15	13,30	2,40	10	16,00	3,00
20	11,00	1,50	15	17,30	2,40	10	18,00	3,00
20	6,00	2,00	15	5,00	2,50	5	20,20	3,00
20	8,00	2,00	15	7,00	2,50	5	22,20	3,00
20	10,00	2,00	15	10,00	2,50	5	24,20	3,00
20	12,00	2,00	15	12,00	2,50	5	26,20	3,00
20	14,00	2,00	15	15,00	2,50	5	30,20	3,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-C	NBR 70 Sh A	425 o-rings	61,33 €

All dimensions in mm

Our other products



NKXR

Combined bearing,
Needle and cylindrical
rollers



PRF_GAL

Roller for aluminium
profile, Fixing kit for
roller concentric



BSM

Spring plunger with
pressure pin, stainless
steel 303 body and
pin



PGM52-M4

Carrying handle,
Brass



TB_ECO

Bevel gear - Steel
C43, 3:1



WJUM20

Drylin® W modular
guidance, Slide



BOXbeta

Dowel pin, Boxed set -
hitch



UGPL

Actuator guide kit,
Long bearing



QUK

Freewheel, With
internal bearing



HG8

Spur gear, Steel
20NCD2



PDD

Spring operated
plunger, Non-rotating
detector shaft



DPAK_DKON

Progressive stop,
Steel

Complementary products



BOX-TOR-TOOL

Box set of Nitrile O-
rings, Extraction tools