

# Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



## Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

## Info

- Ideal for the maintenance department

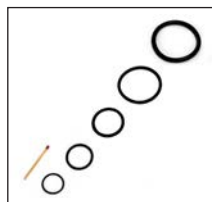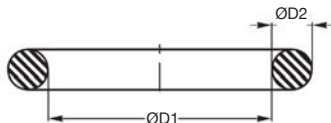

## Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

215

## Our other products



BLHB50

Right angled gearbox, bored shafts, up to 30 Nm



T10\_30\_AL

T type timing pulley, Economy range - T10 aluminium



SLBW

Indexing plunger, weldable, Weldable - Steel



CHCSS

Socket headed screw, Stainless steel - A2



CT

Telescopic universal joint, Normal duty



 
KB\_OP

Open precision linear bearing, Precision - steel



UCFL PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel




B

Steel bevel gear, 1:1



PO

 Pull handle - Multi-sector, Tapped



BETA

Hitch pin, Hitch



GP

Spring loaded toggle latch, With padlock-



BAC105

Storage bin, 8mm

## Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools