

Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

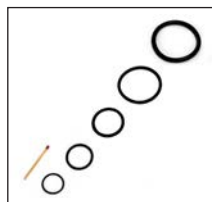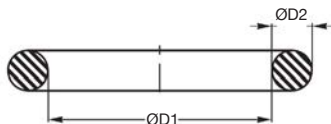

Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

215

Our other products



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



J66

Spur gear coaxial gearbox, from 0.90 to 2.80 Nm - Inline



B_ECO

Bevel gear - Steel C43, 1:1



PLC_PLT

Magnetic stud, With central hole



LRM

Trapezoidal nut, Bronze - 1 thread



BCH_SS

Mushroom headed button, M3 to M8



BUT

Panels accessories, Panel stop



PLA

Magnetic stud, Flat magnet



CLM

Male clevis end, Steel short



Q6

Ball bearing, Steel



TM_CTM_CTF

Suction cup accessory, Insert for suction cup - Tread



GGP

Wing knob "male", Technopolymer with brass spindle

Complementary products



BOX-TOR-TOOL

Box set of Nitrile O-rings, Extraction tools