

Box set of Nitrile O-rings

BOX-TOR-G Diameters 3,00x1,50mm à 30,20x3,00mm


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

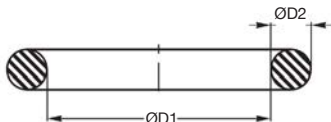

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	13	13,95	2,62	10	28,17	3,53
20	3,68	1,78	13	15,54	2,62	10	29,75	3,53
20	4,48	1,78	13	17,13	2,62	10	31,34	3,53
20	5,28	1,78	13	18,72	2,62	10	32,92	3,53
20	6,07	1,78	13	18,64	3,53	10	34,52	3,53
20	7,66	1,78	10	20,22	3,53	10	36,10	3,53
20	9,25	1,78	10	21,82	3,53	10	37,69	3,53
13	9,19	2,62	10	23,40	3,53	7	37,47	5,34
13	10,78	2,62	10	24,99	3,53	7	40,65	5,34
13	12,37	2,62	10	26,58	3,53	7	43,82	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-G	NBR 70 Sh A	382 o-rings	✓	28,92 €

All dimensions in mm

Our other products



OP3_14_06
Numerical counter accessories,
Reduction socket



PAMF80
Articulated fixable
foot with pressed
base, Ø 80



TR
Round spur rack,
Stainless steel -
module 0,25-1,5



UGH50
H Type Guide units,
For Ø50 actuators



MEP
Cylindrical revolving
handle, Fixed



BH02
Flange with bearing,
Bearing secured with
circlips



ACL-APB
Closing system,
Magnetic door stop



H0
90° crossed axis
helical gear, Steel
20NCD2



QNU
Single row cylindrical
roller bearing, Free
inner ring



DST
Pinion shaft, Stainless
steel 303



BOX-TOR-ORFS
Box set of Nitrile O-
rings, 7.65 x 1.78mm
to 37.82 x 1.78



D19 D29
Compression spring,
by the metre

Complementary products



BOX-TOR-TOOL
Box set of Nitrile O-
rings, Extraction tools