

Box set of Nitrile O-rings

Diameters 3,00x2,00mm à 45,20x4,00mm **BOX-TOR-H**


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

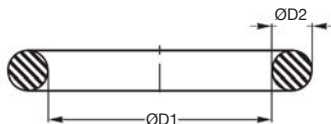

Box contents

Quantity	ØD1	ØD2
18	3,00	2,00
18	4,00	2,00
18	5,00	2,00
18	6,00	2,00
17	7,00	2,00
17	8,00	2,00
17	10,00	2,00
14	10,00	2,50
14	11,00	2,50
14	12,00	2,50

Quantity	ØD1	ØD2
14	14,00	2,50
14	16,00	2,50
14	17,00	2,50
14	19,00	2,50
12	19,00	3,00
12	20,00	3,00
12	22,00	3,00
12	24,00	3,00
12	25,00	3,00
12	27,00	3,00

Quantity	ØD1	ØD2
12	28,00	3,00
12	30,00	3,00
12	32,00	3,00
12	33,00	3,00
12	35,00	3,00
12	36,00	3,00
12	38,00	3,00
9	38,00	4,00
9	42,00	4,00
9	45,00	4,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-H	NBR 70 Sh A	404 o-rings	✓	27,73 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products



TB

Bevel gear - Steel
60C40, 3:1




TB_ECO

Bevel gear - Steel
C43, 3:1



GE

Flexible toggle latch,
Miniature

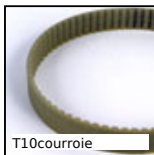

T10courroie

Closed belt, T10 Steel
cored polyurethane



DB

Bevel gear - Steel
60C40, 2:1



CLG1-ALI

Spur gear, Moulded
blue plastic (nylon)



M0

Worm, Non hardened
steel



BTC20_10

Tube end cap,
Standard



CHAE4060PA

Decorative hinges,
Polyamide



PSG15DL

Spur gear - precision
range, Peek



712_001

Threaded spherical
knob, spherical



NDS14C

Suction finger,
Universal angular
connector

Complementary products



BOX-TOR-TOOL

Box set of Nitrile O-
rings, Extraction tools