

Box set of Nitrile O-rings

Diameters 3,00x2,00mm à 45,20x4,00mm **BOX-TOR-H**


- Box set of Nitrile O-rings
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

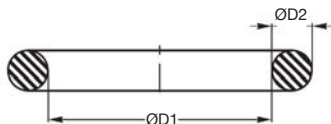

Box contents

Quantity	ØD1	ØD2
18	3,00	2,00
18	4,00	2,00
18	5,00	2,00
18	6,00	2,00
17	7,00	2,00
17	8,00	2,00
17	10,00	2,00
14	10,00	2,50
14	11,00	2,50
14	12,00	2,50

Quantity	ØD1	ØD2
14	14,00	2,50
14	16,00	2,50
14	17,00	2,50
14	19,00	2,50
12	19,00	3,00
12	20,00	3,00
12	22,00	3,00
12	24,00	3,00
12	25,00	3,00
12	27,00	3,00

Quantity	ØD1	ØD2
12	28,00	3,00
12	30,00	3,00
12	32,00	3,00
12	33,00	3,00
12	35,00	3,00
12	36,00	3,00
12	38,00	3,00
9	38,00	4,00
9	42,00	4,00
9	45,00	4,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Stock*	Price each 1 to 2
BOX-TOR-H	NBR 70 Sh A	404 o-rings	✓	27,73 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Our other products




KSTM

Igubal® pillow block bearing, Polymer



STRIP1000

Sealing brush strip, 1m length

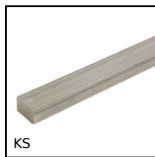

KS

Keysteel, Steel or Stainless steel - Keystock



DCA

Suction cup, 1.5 bellows, silicon



RT70

Self-centering locking Assembly, Medium/high torque



VBFP

Small 6 lobe threaded handle - female, Duroplast - Stainless steel



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



PTAF80-PAMF80

Articulated fixable foot with pressed base Ø80, Ø 80



 
CHAR

Spring hinge for screw mounting, screwed



PLM-C

Flat gripping magnet, Flat holding magnet



G0

Steel spur gear, Steel 20NCD2



AC144

Strike for toggle latch, 22mm

Complementary products



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings, Extraction tools