

Imperial joint kit, NBR90Sh A

BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

Applications

- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for use in the maintenance dept

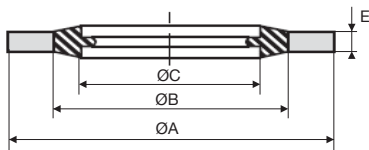

Box contents

Quantity	For thread	A ^{+0.13} ₀	B ^{+0.13}	C ^{+0.13}	E ^{+0.15}
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm

Our other products



PTMC
Telescopic furniture
foot, square plate



NT61
Spur gear coaxial
gearbox, from 5 to 14
Nm - In-line



ES
Simple support base
(bipod), Plastic



NPTR
Adjustable cross
clamp, Adjustable



CHMR40
Worm and wheel gear
reducer, up to 57 Nm



VTHA
Magnetic screw with
hexagonal head, Steel



HCSS
Set screw with
hexagonal socket,
Cup point



GARDLL
Mounting sleeve for
lock pin, Nickel-plated
steel or Stainless steel



SLH-M
Nut for toggle clamp,
Round ended nut for
SLH/SLV clamp



CDPC
Flanged drill bushing,
Steel



CLQ
12.7mm wide steel
feeler strip on rolls,
Feeler strip on rolls



GP
Spring loaded toggle
latch, With padlock-
holder

Complementary products



BOX-TOR-TOOL
Box set of tool for
Nitrile O-rings,
Extraction tools