

Imperial joint kit, NBR90Sh A

BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

Applications

- Suitable for:
- Hydraulic fluids
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for use in the maintenance dept

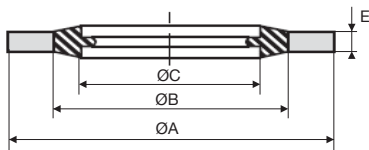

Box contents

Quantity	For thread	A ^{+0,13} ₀	B ^{+0,13}	C ^{+0,13}	E ^{+0,15}
25	1/8"BSP	15,88	11,84	10,37	2,0
25	1/4"BSP	20,57	15,21	13,74	2,0
15	3/8"BSP	23,80	18,75	17,28	2,0
15	1/2"BSP	28,58	23,01	21,54	2,5
15	5/8"BSP	31,75	24,9	23,49	2,5
15	3/4"BSP	34,93	28,53	27,05	2,5
4	1"BSP	42,80	36,88	33,89	3,2

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-INCH	NBR 90 Sh A	114 pieces	55,52 €

All dimensions in mm

Our other products



SVG

Adjustable latch clamp with catch-plate, Stroke from 174mm to 190mm



CT

Telescopic universal joint, Normal duty



E40

Right angle helical reducers, from 2.30 to 20 Nm



SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



CHMR30

Worm and wheel gear reducer, up to 28 Nm



BABreceptacle

Ball pin socket, Socket



MAN

Plain knob, Stainless steel 304



BOX-CSss

Hose clamp, Box set of stainless steel hose clamps



EBM

Steel U bolt, Steel



PTAF80-PAMF80

Articulated levelling foot, pressed bolt-



MCLred

Reducing sleeve, Cylindrical - steel



GLT16

Mini telescopic 3 part slide, Miniature

Complementary products



BOX-TOR-TOOL

Box set of Nitrile O-rings, Extraction tools