

# Boxed set of self tapping inserts

## BOXINS300

## For hard materials

- Selection of self tapping inserts with fine external thread


### Assembly

- Refer to INS300


### Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces

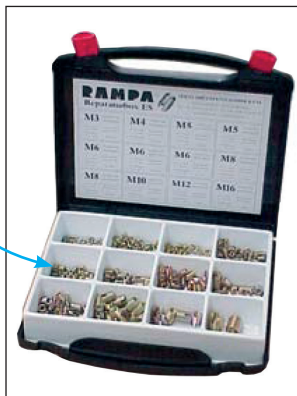

Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

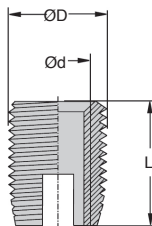

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

\*Depending of availability - Dimensions in mm

 
HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products




GPLny

Brush, nylon



PITAss

 Locking bolt, with T handle



CXS

External circlip  
DIN471, external DIN  
471



SRG

Adjustable latch  
clamp with strike  
plate, Stroke from  
96mm to 121,7mm



CHM50

Worm and wheel gear  
reducer, up to 107  
Nm



BPVMss

Stainless steel  
miniature ball transfer  
unit, Miniature to  
screw



RBGpl

Swivel castor with  
double brake, Steel -  
grey rubber



PCS50

Chain sprocket - steel,  
12.7mm (DIN08B-1)



BABreglable

Adjustable ball pin  
hardened stainless  
steel, adjustable



ACLERP

Roller block for  
aluminium profile,  
Without guide rail



RBGtc

Swivel castor with  
central hole, Steel -  
grey rubber - with



TAC\_SS

Stainless steel rigging  
screw (hook/eye),  
Stainless steel

## Complementary products



INS

Self tapping steel  
insert, Steel



INStool

Insertion tool for self  
tapping inserts,  
Insertion tool



BOX-INS-W

Box set of self tapping  
inserts, Boxed set -  
For wood



INStool

Insertion tool for self  
tapping inserts,  
Insertion tool