

Boxed set of self tapping inserts

BOXINS300

For hard materials

- Selection of self tapping inserts with fine external thread

Assembly

- Refer to INS300


Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces



Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

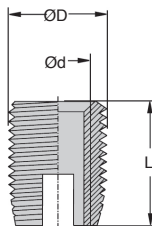

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

*Depending of availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



SCR

Suction cup threaded insert, Insert for suction cup - Socket screw



ACLERP

Roller block for aluminium profile, With guide rail



CM_CO

Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



DKGS

Backlash free coupling Gerwah®, from 0.5 to 3Nm



CHC

Socket headed screw, Steel class 12.19



SHO

Parallel axis helical gear, Machined plastic (delrin)



 
Q4

Double row radial contact ball bearing, Radial contact - Steel



RBGpl

Fixed castor with plate, Steel - grey rubber




UCF_PBT

Stainless steel/Polymer flanged bearing, Polymer and stainless steel



TSM_T10M

 T type timing belt per metre, T10 Steel cored polyurethane



CF

Cam follower, Standard - steel



COA-COG

Surface mounting plate, Surface mounting plate for clevis

Complementary products



INS

Self tapping steel insert, Steel



INStool

Insertion tool for self tapping inserts, Insertion tool



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INStool

Insertion tool for self tapping inserts, Insertion tool