

Boxed set of self tapping inserts

BOXINS300

For hard materials

- Selection of self tapping inserts with fine external thread

Assembly

- Refer to INS300


Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces



Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

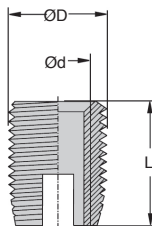

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

*Depending of availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



RBGtc

Swivel castor with central hole, Steel - grey rubber



SLB

Indexing plunger, steel class 5.8



GLT3-46

Telescopic drawer,



PTMC

Telescopic furniture foot, square plate



ACM_AZ

Mounting bracket for bonnet fastener, Hook



PM2

Worm and wheel set, Hardened steel



NK27

Drylin®N miniature guiding system, Width 27 mm




PTA50

Articulated levelling foot, pressed base Ø50, Ø 50




NT121

 Spur gear coaxial gearbox, from 20 to 200 mm



AFM

 Flanged polymer bush, Food grade



H0

Crossed helical gear, crossed axis at 90°



SH1

Parallel axis helical gear, Steel 20NCD2

Complementary products



INS

Self tapping steel insert, Steel



INStool

Insertion tool for self tapping inserts, Insertion tool



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INStool

Insertion tool for self tapping inserts, Insertion tool