

Boxed set of self tapping inserts

BOXINS300

For hard materials

- Selection of self tapping inserts with fine external thread

Assembly

- Refer to INS300


Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces



Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

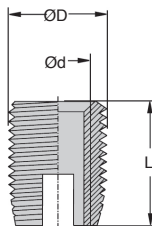

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

*Depending of availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



TUBE25_25

Square Tube,
Aluminium or
Stainless steel



BAC105

Storage bin, 8mm



CHAL3

Piano hinge,
Aluminium



PO

Pull handle - Multi-
sector, Tapped
recessed insert



M0

Worm and wheel set,
Bronze



SLH-M

Nut for toggle clamp,
Round ended nut for
SLH/SLV clamp



SH0

Parallel axis helical
gear, Machined plastic
(delrin)



F7-SF-SM

Multifunction display,
Right angled
mounting bracket



SSDB

Stainless steel bevel
gear, 2:1



PGMT

Pull handle, Stainless
steel



CLQassortiment

Assorted feeler strips,
Assorted feeler strips



STRIPF

Sealing brush strip,
1m length

Complementary products



INS

Self tapping steel
insert, Steel



INStool

Insertion tool for self
tapping inserts,
Insertion tool



BOX-INS-W

Box set of self tapping
inserts, Boxed set -
For wood



INStool

Insertion tool for self
tapping inserts,
Insertion tool