

Boxed set of self tapping inserts

BOXINS300

For hard materials

- Selection of self tapping inserts with fine external thread

Assembly

- Refer to INS300


Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces



Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

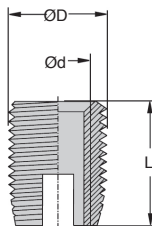

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

*Depending of availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BEAB

Knob for clamping,
Star, anti-bacterial




PRF_PL_4590

Connecting/joining,
Joint plate - 45x90
mm



ACLEFS

Floor anchor,
Adjustable

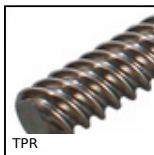

TPR

High helix leadscrew,
Leadscrew only - up to
40mm per rotation



DZY

Cylindrical stop, Steel



PRFRTR

Connecting/joining,
Cross connector



GRP2-14-A

Spring pin, splined
ISO 8741



BAD

Ring brush, Shafts
from Ø9 to Ø68



MURP1932

Mini profile-mounted
adjusting unit,
19x32mm



CLQ

Bearing - accessories,
Feeler strip on rolls



PO

Housing handle - Multi-
sector, Tapped
recessed insert



MSP23

Masterplate®
glueable insert,
Cylindrical Ø23 with
threaded stud

Complementary products



INS

Self tapping insert,
Steel



INStool

Self tapping insert,
Insertion tool



BOX-INS-W

Self tapping insert,
Boxed set - For wood



INStool

Self tapping insert,
Insertion tool