

# Boxed set of self tapping inserts

## BOXINS300

## For hard materials

- Selection of self tapping inserts with fine external thread


### Assembly

- Refer to INS300


### Applications

- For use in aluminium or other non-ferrous metals, thermosetting plastics or hard woods

297 pieces

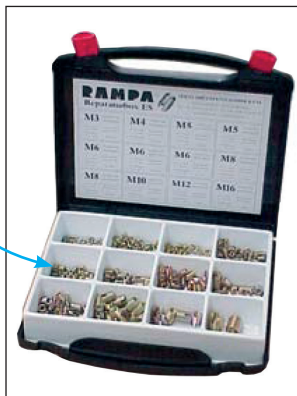

Quantity	ØD	L	Ød
30	M5x0,5	6	M3
50	M6,5x0,75	8	M4
20	M8x1	8	M5
40	M8x1	10	M5
20	M9x1	8	M6
20	M9x1	12	M6
40	M10x1,5	14	M6
20	M12x1,5	12	M8
30	M12x1,5	15	M8
20	M14x1,5	18	M10
5	M16x1,5	22	M12
2	M20x1,5	25	M10

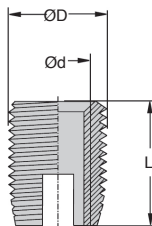

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-INS300	Yellow zinc plated hardened steel	297 pieces	✓	356,56 €

\*Depending of availability - Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



PRF\_CLIP\_22

Cable clip for aluminium profile, For electric and pneumatic cables



ALIDRP240

24V DC power supply, 10 A



 
J51

Spur gear coaxial gearbox, from 0.13 to 0.49 Nm - In-line



PSPT

Flexible tube handle, PVC



RPP

Connecting plate for RPP type timing belts, RPP8



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



CFS

Miniature cam follower, Miniature



BS3

Panamech, Multi-Beam stainless steel, Stainless steel - with set screw




DB

Steel bevel gear, 2:1



EHD04

 Internal epicyclic servo reducers, from 3.4 to 7 Nm



PRZ

Wear strip for slat chain, Z profile to be filled



VPRA\_M

Handwheel with handle, Thermosetting plastic - stainless steel hub

## Complementary products



INS

Self tapping steel insert, Steel



INStool

Insertion tool for self tapping inserts, Insertion tool



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INStool

Insertion tool for self tapping inserts, Insertion tool