

Boxed set of **DIN6885A** keys

Steel or **stainless steel** keys

BOXKK
BOXKKSS

- Round ended keys conforming to DIN6885A (Type A)

Applications

- Ideal for maintenance or workshop applications




Box contents - BOX-KK (steel)

Quantity	W	H	L
10	3	3	15
20	4	4	15
10	5	5	15
20	5	5	20
25	6	6	25
10	6	6	40
5	6	6	90
25	8	7	25
25	8	7	30
20	8	7	40
20	8	7	50
10	8	7	70
5	8	7	100
20	10	8	40
5	10	8	100
20	12	8	36
3	12	8	100
15	14	9	40
10	14	9	50
3	14	9	100

Box contents - BOX-KK/SS (stainless steel)

Quantity	W	H	L
10	4	4	20
10	5	5	20
10	6	6	20
10	6	6	25
10	6	6	40
10	8	7	25
5	8	7	35
2	8	7	130
10	10	8	25
2	12	8	90

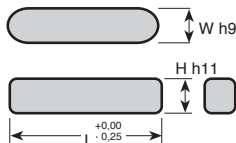

INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-KK	steel	281 pieces	✓	125,63 €
BOX-KK/SS	stainless steel	79 pieces	✓	193,57 €

*Depending on availability - Dimensions in mm

Our other products



ACAss

Stainless steel splined shaft, Stainless steel



LRM

Trapezoidal bronze nut, Bronze - 1 thread



PCS62SS

Chain sprocket - Stainless steel, 15.875mm (DIN 08B-1)



PITAss

Locking bolt, with T handle



AC144

Strike for toggle latch, 22mm



CDP

Flanged drill bushing, Steel



PW_PWG25

Worm - precision range, Steel



PRS100

Stainless steel articulated foot Ø100, Ø 100



BPLE

Ball transfer unit push fit, Light



CLB_T

Die cast zinc clamping lever - male, Zamak



PRF_SDD

Support for Ø12mm Prox detector, Ø12



RPCpl

Swivel castor with double brake, Steel - Polyamide

Complementary products



KK

Rounded end feather key, Steel



KKSS

Rounded end feather key, Stainless steel