

Boxed set of **DIN6885A** keys

Steel or **stainless steel** keys

BOXKK
BOXKKSS

- Round ended keys conforming to DIN6885A (Type A)

Applications

- Ideal for maintenance or workshop applications




Box contents - BOX-KK (steel)

Quantity	W	H	L
10	3	3	15
20	4	4	15
10	5	5	15
20	5	5	20
25	6	6	25
10	6	6	40
5	6	6	90
25	8	7	25
25	8	7	30
20	8	7	40
20	8	7	50
10	8	7	70
5	8	7	100
20	10	8	40
5	10	8	100
20	12	8	36
3	12	8	100
15	14	9	40
10	14	9	50
3	14	9	100

Box contents - BOX-KK/SS (stainless steel)

Quantity	W	H	L
10	4	4	20
10	5	5	20
10	6	6	20
10	6	6	25
10	6	6	40
10	8	7	25
5	8	7	35
2	8	7	130
10	10	8	25
2	12	8	90

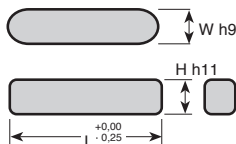

INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-KK	steel	281 pieces	✓	125,63 €
BOX-KK/SS	stainless steel	79 pieces	✓	193,57 €

*Depending on availability - Dimensions in mm

Our other products



SSG0
Stainless steel spur gear, Stainless steel 304L



PRF_PSA
Shaft support for aluminium profile, Linear guide shaft



AT5-BAR
AT type tooth bar stock, AT5



H02SS
Needle roller universal joint - Stainless steel, Heavy duty



NSO
Housing for open linear bearing, Opened - long



PP50
Worm and wheel gear reducer, from 6.50 to 12.80 Nm



G4-ECO
Eco range Spur gear, Steel C45



FF40
Offset spur gear reducer, from 59 to 210 Nm



FF50
Offset spur gear reducer, from 111 to 425 Nm



SHA
Handwheel without handle, Polyamide



SCE_SS
Stainless steel U-shaped clamp, Stainless steel



PTA50
Articulated levelling foot, pressed base $\varnothing 50$, $\varnothing 50$

Complementary products



KK
Rounded end feather key, Steel



KKSS
Rounded end feather key, Stainless steel