

# Boxed set of **DIN6885A** keys

Steel or **stainless steel** keys

**BOXKK**  
**BOXKKSS**

- Round ended keys conforming to DIN6885A (Type A)

## Applications

- Ideal for maintenance or workshop applications




### Box contents - BOX-KK (steel)

Quantity	W	H	L
10	3	3	15
20	4	4	15
10	5	5	15
20	5	5	20
25	6	6	25
10	6	6	40
5	6	6	90
25	8	7	25
25	8	7	30
20	8	7	40
20	8	7	50
10	8	7	70
5	8	7	100
20	10	8	40
5	10	8	100
20	12	8	36
3	12	8	100
15	14	9	40
10	14	9	50
3	14	9	100

### Box contents - BOX-KK/SS (stainless steel)

Quantity	W	H	L
10	4	4	20
10	5	5	20
10	6	6	20
10	6	6	25
10	6	6	40
10	8	7	25
5	8	7	35
2	8	7	130
10	10	8	25
2	12	8	90

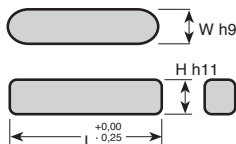

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Material	Quantity per box	Stock*	Price each
BOX-KK	steel	281 pieces	✓	125,63 €
BOX-KK/SS	stainless steel	79 pieces	✓	193,57 €

\*Depending on availability - Dimensions in mm

## Our other products



PRES7HR

Manual workbench press, Force up to 700kg



ZHBRA

Plastic bevel gear, 1,25:1 2:1 3:1



VQTplqn

Quarter-turn clamp lock - Clamping plate, Flush mounting



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter



CABma

Swaging sleeve for fitting cable, To crimp a wire rope



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



ACL-PR

Joining plate for aluminium profile, Right angled connection




PSG2

Spur gear - precision range, Case hardened steel 20NCD2



PMC48\_M8

 Anti-vibration machine mount, Oval base plate



PX\_PO

Carrying handle, standard



WW16

Drylin® W slide, slide assembly



TBD

Manual leadscrew table with opposing threads, 2kg

## Complementary products



KK

Rounded end feather key, Steel



KKSS

Rounded end feather key, Stainless steel