

Boxed set of half round (Woodruff) keys NFE22179

BOXKU

Steel keys

- Half round keys conforming to NFE22179 (DIN6888)


Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	A(h9)	B(h11)	C(h11)
50	3	3,7	10
50	4	5,0	13
25	5	6,5	16
25	5	7,5	19
25	6	9,0	22
25	6	10,0	25
15	8	11,0	28
10	8	13,0	32
2	8	15,0	38
2	10	16,0	45
1	12	19,0	65
1	12	24,0	80

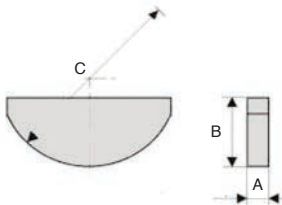

INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Stock*	Price each
BOX-KU	231 pieces	✓	209,67 €

*Depending on availability - Dimensions in mm

Our other products



RCC_RCX
Spherical tilt washer -
DIN6319, convex



SDC
Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12



GMK17_BROSSE
Brush strip, Cone-
shaped - brush



 
LR
Precision locknut,
Precision locknut



SA_SAKH
Housing for linear
bearing, Closed - light
load



ACLLPP
Latch for aluminium
profile, Spring
operated latch



G0
Steel spur gear, Steel
20NCD2



DOG319
Motor-gearbox 12V
and 24V DC, from 4 to
9 Nm



RUR
Wheel, Polyurethane -
Aluminium rim (Free
running)



PT821
Drive sprocket for slat
top chain, Ranges 821
and 805



RVM14
Manual worm and
wheel gearbox,
Worm/wheel



Q4
Double row radial
contact ball bearing,
Radial contact - Steel

Complementary products



BOXKK
Boxed set of
DIN6885A keys,
Boxed set - Steel or
stainless steel