

Boxed set of half round (Woodruff) keys NFE22179

BOXKU

Steel keys

- Half round keys conforming to NFE22179 (DIN6888)


Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	A(h9)	B(h11)	C(h11)
50	3	3,7	10
50	4	5,0	13
25	5	6,5	16
25	5	7,5	19
25	6	9,0	22
25	6	10,0	25
15	8	11,0	28
10	8	13,0	32
2	8	15,0	38
2	10	16,0	45
1	12	19,0	65
1	12	24,0	80

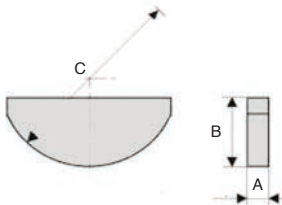

INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Stock*	Price each
BOX-KU	231 pieces	✓	209,67 €

*Depending on availability - Dimensions in mm

Our other products



NKXR
Combined bearing without inner ring, Needle and cylindrical rollers



PTA100
Articulated levelling foot, pressed base
Ø100, Ø 100



FGWA
End support, With base




AT10courroie
AT type timing belt, AT10 Steel cored polyurethane



RCX-6
Spherical tilt washer - DIN6319, convex



LVT
Miniature motorised actuator 4A, 4 amperes

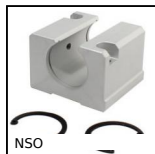

NSO
Housing for open linear bearing, Opened - long



H0
Crossed helical gear crossed axis at 90°, Steel 20NCD2



 
DCA
Suction cup, 1.5 bellows, natural rubber



BWU
Compact precision slide, from 1510 N to 10500 N



BAGSS
Stainless steel Clamping collar, Stainless steel



MET
Cylindrical sintered bronze bush, Self-lubricating sintered bronze

Complementary products



BOXKK
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel