

Boxed set of cylindrical dowel pins **DIN6325**

Steel dowel pins

BOX_{DH}

- Steel pins conforming to DIN6325

 
Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	ØD	L
100	2	10
50	2	32
100	3	10
50	3	20
100	4	10
30	4	24
50	5	12
40	5	24
30	5	36
50	6	10
40	6	16
30	6	20
25	6	30
20	6	40
30	8	20
20	8	40
20	10	24
10	10	40
10	12	40



✓ INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request


Part number	Quantity per box	Stock*	Price each
BOX-DH	805 pieces	✓	128,45 €

*Depending on availability - Dimensions in mm

Our other products



ERT
Sliding nut, For T slot

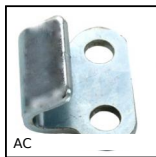

AC
Strike for toggle latch,
18mm



QNUP
Single row cylindrical
roller bearing, 1 fixed
inner flange and 1 fr...



GARBAB
Lock pin for clamping,
Ball lock pin




P70
Worm and wheel gear
reducer, up to 164
Nm



SLV
Vertical toggle clamp,
Vertical Lever Clamp -
stainless steel



 CHM63-MOT
Asynchronous AC
motorgearboxes 0.37
to 1.5kW, 0.37 to
1.5kW



M1
Worm and wheel set,
Machined plastic
(delrin)



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



CLG1
Moulded plastic spur
gear, Moulded plastic



PM3
Worm and wheel set,
Machined plastic



PENC
Recessed handle, clip-
in

Complementary products



DH
Dowel pin, Solid DIN
6325