

# Boxed set of threaded dowel pins **DIN7979D**

## BOXDHX

## Steel pins

- Threaded dowel pins conforming to DIN7979D


### Applications

- Ideal for maintenance or workshop applications



### Box contents

Quantity	ØD	L
30	5	20
20	6	24
20	6	30
20	8	24
20	8	30
20	8	40
20	10	30
15	12	40
10	16	60

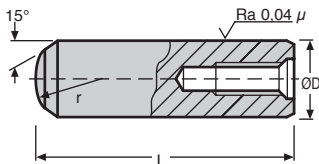

**INCREASED STOCK**

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number      Quantity per box

BOX-DHX      175 pieces

Stock\*



Price each

168,26 €

\*Depending on availability - Dimensions in mm

## Our other products




Female rod ends,  
Stainless steel / PTFE



Articulated levelling  
foot, pressed base  
Ø100, Ø 100



Hexagonal ended  
handle, Hexagonal  
ended handle

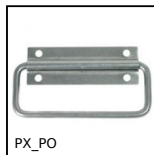

Carrying handle,  
standard



Screwjack with  
travelling nut, with  
moving nut



Swivel castor with  
double brake,  
Stainless steel -  
Polyamide



 
Locking bolt, with T  
handle



Optional output shaft  
stainless steel, P  
gearboxes double  
sided outp...



Floor anchor for  
aluminium profile,  
Adjustable



Worm and wheel gear  
reducer, up to 8.8 Nm



High Temperature  
Castor, up to 200kg



Indexing plunger with  
flange, with drilled  
flange

## Complementary products



Dowel pin internal  
thread, Extractable  
DIN 7979D