

# Boxed set of threaded dowel pins **DIN7979D**

## BOXDHX

## Steel pins

- Threaded dowel pins conforming to DIN7979D


### Applications

- Ideal for maintenance or workshop applications



### Box contents

Quantity	ØD	L
30	5	20
20	6	24
20	6	30
20	8	24
20	8	30
20	8	40
20	10	30
15	12	40
10	16	60

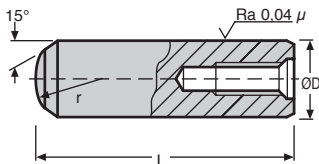

**INCREASED STOCK**

### DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number      Quantity per box

BOX-DHX      175 pieces

Stock\*



Price each

168,26 €

\*Depending on availability - Dimensions in mm

## Our other products



ACLBTS

Closing system for aluminium profile, Spacer for spherical ended stop



HLU

Spoked handwheel without handle, Aluminium




HDSS

Needle roller double universal joint - Stainless steel, Heavy duty



SVR30

Screwjack with travelling nut, with moving nut

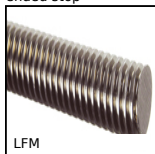

LFM

Steel leadscrew, Medium carbon steel - 1 thread



PITA

Locking bolt, with T handle



SHS

Shoulder screw stainless steel 303, Stainless steel 303



 
T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



SF\_ZZ

Deep groove ball bearing, Stainless steel



CAB

Stainless steel cable, Stainless steel



VT

Vari-Tork® slip friction clutch, 0.53 to 1.32 Nm



PSG15

Spur gear - precision range, Pre-hardened Steel 35NCD6

## Complementary products



DHX

Dowel pin internal thread, Extractable DIN 7979D