

Boxed set of threaded dowel pins DIN7979D

BOXDHX

Steel pins

- Threaded dowel pins conforming to DIN7979D


Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	ØD	L
30	5	20
20	6	24
20	6	30
20	8	24
20	8	30
20	8	40
20	10	30
15	12	40
10	16	60

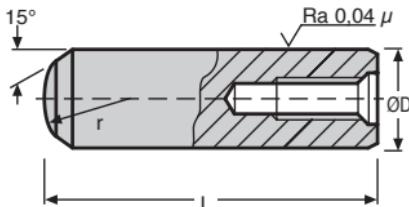

✓ INCREASED STOCK

DISCOUNTS

Qty	1+	2+	5+
Disc.	List -5%	On request	

Part number	Quantity per box	Stock*	Price each
BOX-DHX	175 pieces	✓	168,26 €

*Depending on availability - Dimensions in mm

Our other products



RFVbr

Stainless steel reaction arm,
Reaction arm



UCP_SS

Stainless steel pillow
block bearing,
Stainless steel



FDSQ

Flexible drive shaft,
Masterflex® Steel,
with PVC casing



PWC

Powercoil thread
inserts, Kit Powercoil -
with or without
insertion ...



EHD06

Internal epicyclic
servo reducers, from
8 to 19 Nm



MEP

Revolving handle for
handwheel, Fixed



CHAu

Screwed hinge, 270°



PRF_GAL

Roller for aluminium
profile, Fixing kit for
roller eccentric



HCSS

Set screw with
hexagonal socket,



RVM14

Manual worm and
wheel gearbox,



BPHF

Ball transfer unit push
fit, Heavy



PCAtherm

Pull handle,
Thermoplastic

Complementary products



DHX

Dowel pin internal
thread, Extractable
DIN 7979D