

# Boxed set of spring pins ISO 8752

Steel spring pins

BOXSAP

- Steel spring pins conforming to ISO 8752


## Applications

- Ideal for maintenance or workshop applications



## Box contents

Quantity	ØD	L
50	2	20
50	3	30
50	3	40
50	4	30
50	4	40
50	4	54
30	5	40
30	5	50
20	5	60
20	6	40
20	6	5
20	6	60
10	8	30
10	8	40
10	8	50
10	8	60
10	8	80
5	10	40
5	10	80

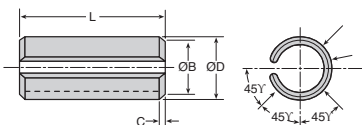

## DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Stock*	Price each
BOX-SAP	500 pieces	✓	96,37 €

\*Depending on availability - Dimensions in mm

## Our other products



PCS37K

Chain sprocket with hardened teeth, 9.525mm (DIN06B-1)



BOX-NINA

Self locking nut - DIN985, Box set of steel nuts



PPJ

Indexing plunger with flange, With horizontal mounting flange and pu...



PRF\_ART

Articulated bracket for use with aluminium profile, Standard flange




SH0

Parallel axis helical gear, Machined plastic (delrin)




CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW

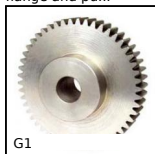

G1

Steel spur gear, Steel 20NCD2

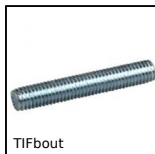

TIFbout

Threaded stud - DIN976A, Steel



ES

Bipod support base, Plastic



SH0

Parallel axis helical gear, Steel 20NCD2



RDCss

Rigging screw with 2 jaws stainless steel,



PR65C

Half-articulated foot Ø 65, Ø 65

## Complementary products



SRP

Slotted spring pin ISO8752, Split ISO 8752