

Boxed set of spring pins ISO 8752

Steel spring pins

BOXSAP

- Steel spring pins conforming to ISO 8752


Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	ØD	L
50	2	20
50	3	30
50	3	40
50	4	30
50	4	40
50	4	54
30	5	40
30	5	50
20	5	60
20	6	40
20	6	5
20	6	60
10	8	30
10	8	40
10	8	50
10	8	60
10	8	80
5	10	40
5	10	80

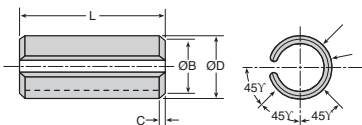

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Stock*	Price each
BOX-SAP	500 pieces	✓	96,37 €

*Depending on availability - Dimensions in mm

Our other products



DER71

Stainless steel AC asynchronous motor 0.25 à 0.37kW, 0.25 to 0.37kW



VHTM

Hexagonal headed screw Hygienic Design®, Stainless steel



T10courroie

T type timing belt, T10 Steel cored polyurethane



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel



TCC

Rigging screw (hook/hook), Steel



BSM_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



G0

Steel spur gear, Steel 20NCD2



RT25

Self-centering flanged locking assembly, Medium/high torque



UFX

Uneflex® elastic coupling, range



RURt

Swivel castor with central hole, Polyurethane -



GCL

Linear ball slide Eco Range, economy range



ADL_M

Male eye bolt conforms to DIN580, Steel

Complementary products



SRP

Slotted spring pin ISO8752, Split ISO 8752