

Boxed set of spring pins ISO 8752

Steel spring pins

BOXSAP

- Steel spring pins conforming to ISO 8752


Applications

- Ideal for maintenance or workshop applications



Box contents

Quantity	ØD	L
50	2	20
50	3	30
50	3	40
50	4	30
50	4	40
50	4	54
30	5	40
30	5	50
20	5	60
20	6	40
20	6	5
20	6	60
10	8	30
10	8	40
10	8	50
10	8	60
10	8	80
5	10	40
5	10	80

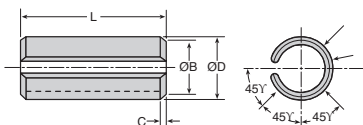

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	Quantity per box	Stock*	Price each
BOX-SAP	500 pieces	✓	96,37 €

*Depending on availability - Dimensions in mm

Our other products



EBH

Cap nut Hygienic Design®, With collar



PRF4532

Standard aluminium profile, 45 x 32 mm



D19 D29

Compression springs in metre length steel, by the metre



PSG05HC

Skive hobbed spur gears - precision range, Case hardened steel 20NCD2



F7-I

Multifunction display, With internal sensor




GPBSS

Threaded spherical knob, Aluminium



AT10-50ECO

AT type timing pulley, Economy range - AT10 aluminium

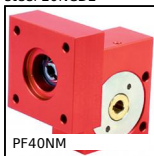

PF40NM

Worm and wheel gear reducer, up to 18 Nm



CAP815

Slim slat top chain stainless steel, Narrow range 815



HTD14M_55

HTD Heavy duty timing pulley, HTD14 Steel



ACLLPP

Latch for aluminium profile, Spring operated latch



CFF_SS

Female rod ends DIN ISO12240-4, Stainless steel / bronze - Economy r...

Complementary products



SRP

Slotted spring pin ISO8752, Split ISO 8752