





## BPFL

## 2 mounting points

- Pressed sheet steel
- Material : steel

### Uses

- Simple mounted bearing for light loads

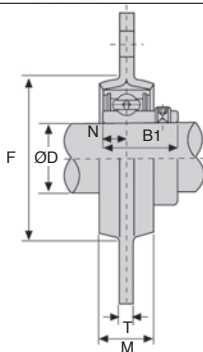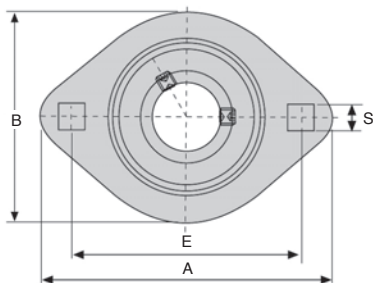

### Load (kN)

| Part number | Dynamic C | Static Co |
|-------------|-----------|-----------|
| BPFL201     | 9,2       | 4,48      |
| BPFL202     | 9,2       | 4,48      |
| BPFL203     | 9,2       | 4,48      |
| BPFL204     | 12,2      | 6,30      |
| BPFL205     | 13,3      | 7,46      |
| BPFL206     | 18,5      | 10,80     |
| BPFL207     | 24,5      | 14,60     |

### DISCOUNTS

| Qty   | 1+   | 6+   | 20+  | 40+  | 60+        |
|-------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | On request |

| Part number | ØD | A   | E     | B  | M  | S    | T   | F (min) | Bolt size | B1 | N   | Weight (kg) | Stock* | Price each 1 to 5 |
|-------------|----|-----|-------|----|----|------|-----|---------|-----------|----|-----|-------------|--------|-------------------|
| BPFL201     | 12 | 81  | 63,5  | 59 | 14 | 7,1  | 4,0 | 49      | M6        | 22 | 6,0 | 0,19        | ✓      | 9,11 €            |
| BPFL202     | 15 | 81  | 63,5  | 59 | 14 | 7,1  | 4,0 | 49      | M6        | 22 | 6,0 | 0,19        | ✓      | 9,15 €            |
| BPFL203     | 17 | 81  | 63,5  | 59 | 14 | 7,1  | 4,0 | 49      | M6        | 22 | 6,0 | 0,19        | ✓      | 9,50 €            |
| BPFL204     | 20 | 90  | 71,5  | 67 | 16 | 9,0  | 4,0 | 56      | M8        | 25 | 7,0 | 0,24        | ✓      | 9,99 €            |
| BPFL205     | 25 | 95  | 76,0  | 71 | 18 | 9,0  | 4,0 | 60      | M8        | 27 | 7,5 | 0,28        | ✓      | 11,19 €           |
| BPFL206     | 30 | 113 | 90,5  | 84 | 18 | 11,0 | 5,2 | 71      | M10       | 30 | 8,0 | 0,38        | ✓      | 14,76 €           |
| BPFL207     | 35 | 122 | 100,0 | 94 | 20 | 11,0 | 5,2 | 81      | M10       | 32 | 8,5 | 0,50        | ✓      | 17,38 €           |

\*Depending on availability - Dimensions in mm

## Our other products



PRF\_ECL  
Nut for aluminium profile, Stainless steel square nut with tab



GARQT  
Quarter turn lock pin for clamping, Quarter turn



GG1  
Ground spur gear, Heat treated steel



RHttcss  
High Temperature Castor, up to 200kg



GPLso  
Brush, silk



RFK48B  
Hypoid gearbox - Stainless steel, up to 350 Nm



AT10courroie  
AT type timing belt, AT10 Steel cored polyurethane



 
BPPL  
Mini plain bearing ball transfer unit, For countersinking



PHTss  
Pull handle, Up to 250 °C



RBS  
Dynamic washer DIN2093, Steel



RPP14  
RPP heavy duty timing belt, RPP14



MAX22  
Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm

## Complementary products



BPF  
Sheet steel flanged bearing for light loads, Sheet steel



BPP  
Pressed steel flanged bearing for light loads, Sheet steel



BPFLss  
Pressed stainless steel flange bearing, Stainless steel