





## BPFL

## 2 mounting points

- Pressed sheet steel
- Material : steel

### Uses

- Simple mounted bearing for light loads

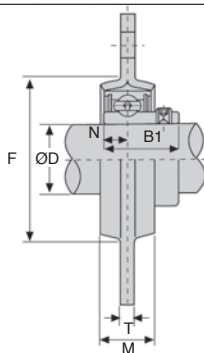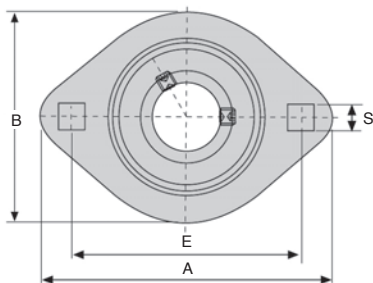

### Load (kN)

Part number	Dynamic C	Static Co
BPFL201	9,2	4,48
BPFL202	9,2	4,48
BPFL203	9,2	4,48
BPFL204	12,2	6,30
BPFL205	13,3	7,46
BPFL206	18,5	10,80
BPFL207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	B	M	S	T	F (min)	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPFL201	12	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	9,11 €
BPFL202	15	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	9,15 €
BPFL203	17	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	9,50 €
BPFL204	20	90	71,5	67	16	9,0	4,0	56	M8	25	7,0	0,24	✓	9,99 €
BPFL205	25	95	76,0	71	18	9,0	4,0	60	M8	27	7,5	0,28	✓	11,19 €
BPFL206	30	113	90,5	84	18	11,0	5,2	71	M10	30	8,0	0,38	✓	14,76 €
BPFL207	35	122	100,0	94	20	11,0	5,2	81	M10	32	8,5	0,50	✓	17,38 €

\*Depending on availability - Dimensions in mm

## Our other products



GCH

Linear ball slide -  
Stainless steel balls,  
Chariot - from 514 N  
to 1...



GPB55

Threaded spherical  
knob, Stainless steel  
304



DB

Steel bevel gear, 2:1



H0

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



PSG15S

Spur gear - precision  
range, Stainless steel  
316



J66

Spur gear coaxial  
gearbox, from 0.90 to  
2.80 Nm - In-line



BPHT

Ball transfer unit bolt  
fitting, Heavy



DB

Steel bevel gear, 2:1



PW\_PWG2

Worm - precision  
range, Stainless steel



CHMX\_CHMDX

Shaft for worm and  
wheel reducer CHMR



TIF

Threaded rod -  
DIN975, Stainless



PCS\_PA6

Plastic sprocket,  
9.525mm (DIN 06B-1)

## Complementary products



BPF

Sheet steel flanged  
bearing for light  
loads, Sheet steel



BPP

Pressed steel flanged  
bearing for light  
loads, Sheet steel



BPFLss

Pressed stainless  
steel flange bearing,  
Stainless steel