




## BPP

## 2 mounting points

- Pressed sheet flanged bearing
- Material : steel

### Use

- Mounting single bearing (light loads only)

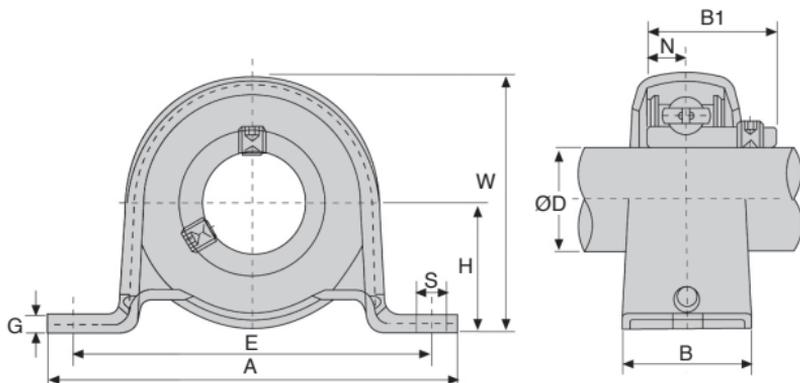

Part number	Load (kN)	
	Dynamic C	Static Co
BPP201	9,2	4,48
BPP202	9,2	4,48
BPP203	9,2	4,48
BPP204	12,2	6,30
BPP205	13,3	7,46
BPP206	18,5	10,80
BPP207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP201	12	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	12,18 €
BPP202	15	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	12,25 €
BPP203	17	22,2	86	68	25	9,5	3,2	43,8	M8	22	6,0	0,19	✓	12,72 €
BPP204	20	25,4	98	76	32	9,5	3,2	50,5	M8	25	7,0	0,23	✓	14,20 €
BPP205	25	28,6	108	86	32	11,5	4,0	56,6	M10	27	7,5	0,28	✓	15,00 €
BPP206	30	33,3	117	95	38	11,5	4,0	66,3	M10	30	8,0	0,47	✓	20,61 €
BPP207	35	39,7	129	106	42	11,5	4,6	78,0	M10	32	8,5	0,57	-	24,17 €


\*Depending on availability - Dimensions in mm



- Pressed sheet steel
- Material : steel

### Use

- Mounting single bearing (light loads only)

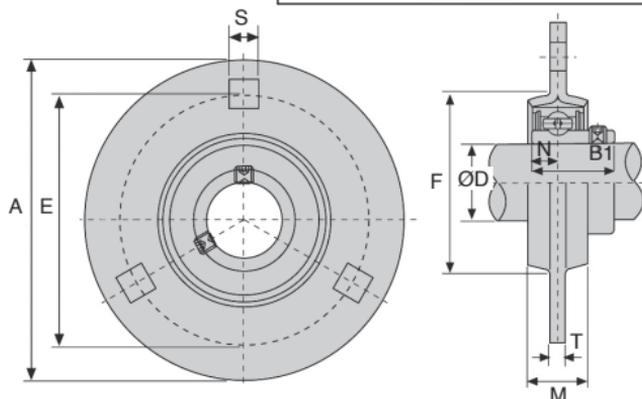

Part number	Load (kN)	
	Dynamic C	Static Co
BPF201	9,2	4,48
BPF202	9,2	4,48
BPF203	9,2	4,48
BPF204	12,2	6,30
BPF205	13,3	7,46
BPF206	18,5	10,80
BPF207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	M	S	T	F (min)	Bolt size	B1	N	Weight (kg)	Stock*	Price each
												1 to 5	
BPF201	12	81	63,5	14	7,1	4,0	49	M6	22	6,0	0,27	✓	12,29 €
BPF202	15	81	63,5	14	7,1	4,0	49	M6	22	6,0	0,27	✓	12,38 €
BPF203	17	81	63,5	14	7,1	4,0	49	M6	22	6,0	0,27	✓	12,84 €
BPF204	20	90	71,5	16	9,0	4,0	56	M8	25	7,0	0,33	✓	15,18 €
BPF205	25	95	76,0	18	9,0	4,0	60	M8	27	7,5	0,38	✓	15,99 €
BPF206	30	113	90,5	18	11,0	5,2	71	M10	30	8,0	0,62	✓	23,48 €
BPF207	35	122	100,0	20	11,0	5,2	81	M10	32	8,5	0,82	✓	27,00 €

\* Depending on availability - Dimensions in mm





## BPFL

## 2 mounting points

- Pressed sheet steel
- Material : steel

### Use

- Mounting single bearing (light loads only)

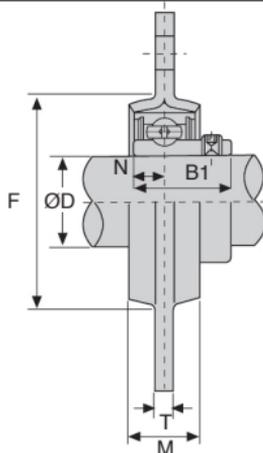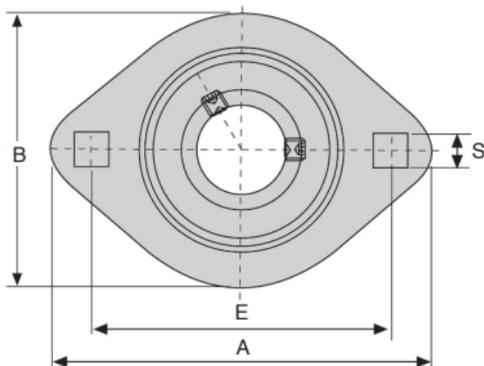

### Load (kN)

Part number	Dynamic C	Static Co
BPFL201	9,2	4,48
BPFL202	9,2	4,48
BPFL203	9,2	4,48
BPFL204	12,2	6,30
BPFL205	13,3	7,46
BPFL206	18,5	10,80
BPFL207	24,5	14,60

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	B	M	S	T	F (min)	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPFL201	12	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	11,84 €
BPFL202	15	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	11,87 €
BPFL203	17	81	63,5	59	14	7,1	4,0	49	M6	22	6,0	0,19	✓	12,33 €
BPFL204	20	90	71,5	67	16	9,0	4,0	56	M8	25	7,0	0,24	✓	12,97 €
BPFL205	25	95	76,0	71	18	9,0	4,0	60	M8	27	7,5	0,28	✓	14,52 €
BPFL206	30	113	90,5	84	18	11,0	5,2	71	M10	30	8,0	0,38	✓	19,16 €
BPFL207	35	122	100,0	94	20	11,0	5,2	81	M10	32	8,5	0,50	-	22,57 €

\*Depending on availability - Dimensions in mm

# Pressed stainless steel bearing for light loads


2 mounting holes

BPPSS

- Pressed sheet steel housing
- Material: stainless steel

## Application

- Mounting a simple bearing, suitable for light loads only

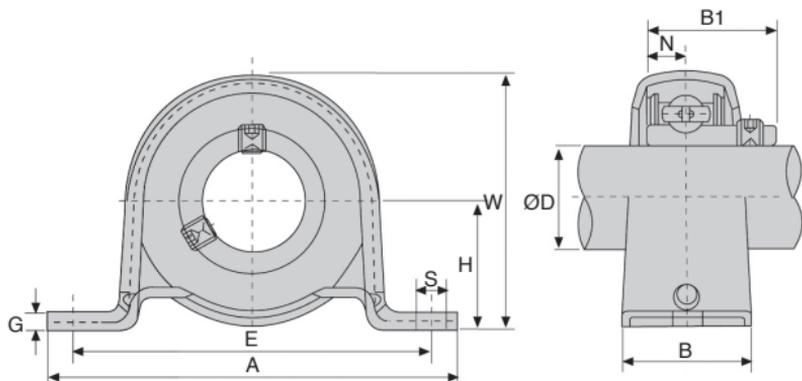

Part number	Load (kN)	
	Dynamic C	Static Co
BPP204/SS	12,80	6,65
BPP205/SS	14,00	7,85
BPP206/SS	19,50	11,30
BPP207/SS	25,70	15,30

## DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	H	A	E	B	S	G	W	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPP204/SS	20	25,4	98	76	32	9	3,2	50	M8	25	7	0,22	✓	22,05 €
BPP205/SS	25	28,6	108	86	32	11	4	56	M10	27	7,5	0,29	✓	25,39 €
BPP206/SS	30	33,3	117	95	38	11	4	66	M10	30	8	0,43	✓	29,12 €
BPP207/SS	35	39,7	129	106	42	11	5	78	M10	32	8,5	0,63	-	54,99 €

\*Depending on availability - Dimensions in mm

# Pressed stainless steel bearing for light loads

## BPFSS Flange with 3 mounting holes


- Pressed sheet steel housing
- Material: stainless steel

### Application

- Mounting a simple bearing, suitable for light loads only



stainless steel

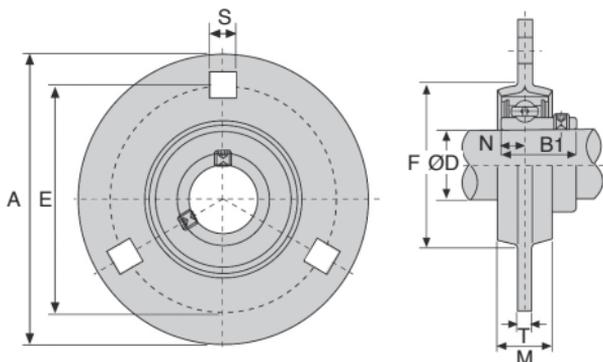

Part number	Load (kN)	
	Dynamic C	Static Co
BPF204/SS	12,80	6,65
BPF205/SS	14,00	7,85
BPF206/SS	19,50	11,30
BPF207/SS	25,70	15,30

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	T	M	S	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPF204/SS	20	90	71	2	16	9	56	M8	25	7	0,29	✓	21,07 €
BPF205/SS	25	95	76	2	18	9	60	M8	27	7,5	0,34	✓	25,52 €
BPF206/SS	30	113	90	2,6	18	11	71	M8	30	8	0,55	✓	40,76 €
BPF207/SS	35	122	100	2,6	20	11	81	M10	32	8,5	0,69	-	43,84 €

\*Depending on availability - Dimensions in mm

# Flanged sheet **stainless steel** housing for light loads



Flange with 2 mounting holes

**BPFLSS**

- Pressed sheet steel housing
- Material: stainless steel

## Application

- Mounting a simple bearing, suitable for light loads only

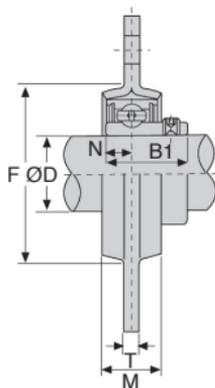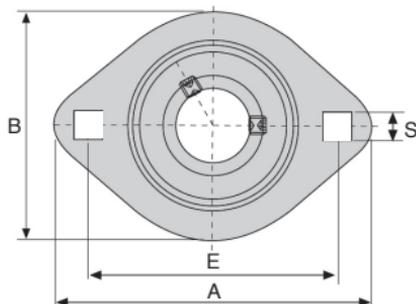

Part number	Load (kN)	
	Dynamic C	Static Co
BPFL204/SS	12,80	6,65
BPFL205/SS	14,00	7,85
BPFL206/SS	19,50	11,30
BPFL207/SS	25,70	15,30

## DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	B	M	S	T	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPFL204/SS	20	90	71	67	16	8,7	2	55,5	M8	25	7	0,22	✓	19,39 €
BPFL205/SS	25	95	76	71	18	8,7	2	60,5	M8	27	7,5	0,27	✓	23,99 €
BPFL206/SS	30	113	90,5	84	18	10,3	2,6	71,5	M10	30	8	0,41	✓	33,70 €
BPFL207/SS	35	122	100	94	20	10,5	2,6	81,0	M10	32	8,5	0,55	-	57,81 €

\*Depending on availability - Dimensions in mm