

# Flanged sheet stainless steel housing for light loads

Flange with 2 mounting holes

BPFLSS




- Palier tôle emboutie
- Matière :  
inox

## Application

- Mounting a simple bearing, suitable for light loads only

**NEW:**  
stainless steel  
range

stainless  
steel

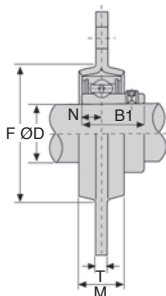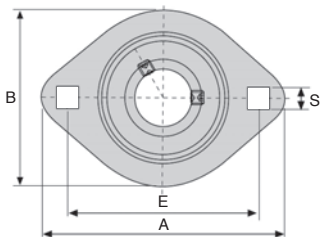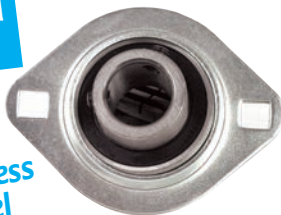

## DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	B	M	S	T	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPFL204/SS	20	90	71	67	16	8,7	2	55,5	M8	25	7	0,22	✓	18,48 €
BPFL205/SS	25	95	76	71	18	8,7	2	60,5	M8	27	7,5	0,27	✓	21,67 €
BPFL206/SS	30	113	90,5	84	18	10,3	2,6	71,5	M10	30	8	0,41	✓	32,11 €
BPFL207/SS	35	122	100	94	20	10,5	2,6	81,0	M10	32	8,5	0,55	-	55,06 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

## Our other products



PAV

Fixed anti-vibration  
foot mount, Vibration-  
dampening



ERT

Sliding nut, For T slot



HSS

Shoulder screw  
ISO7379, Hardened  
Steel class 12.9



PM3

Worm and wheel set,  
Non hardened steel



MPB

Hexagonal spacer,  
Brass



PRF\_PA

Angle plate for  
aluminium profile,  
Adjustable plate



NKIB

Combined bearing  
with inner ring, Axial  
load in both directions




YG1

HEAVY DUTY spur  
gear, Steel 35NCD6




T10courroie

 T type timing belt,  
T10 Steel cored



MBrondelle

 Stop washer, Stop  
washer MB



CHTRB

Single and dual  
output gearboxes, Up



STL

Guidance brush - Rail,  
Rail

## Complementary products



BPPss

Pressed stainless  
steel pillow block,  
Stainless steel



BPFss

Pressed stainless  
steel flange bearing,  
Stainless steel



BPFL

Sheet steel flanged  
bearing for light  
loads, Sheet steel



UCFL\_SS

Stainless steel flanged  
bearing, Stainless  
steel