

# Pressed stainless steel bearing for light loads

## BPFSS

## Flange with 3 mounting holes

- Pressed sheet steel housing
- Material: stainless steel


**NEW:**  
stainless steel  
range

### Application

- Mounting a simple bearing, suitable for light loads only



stainless  
steel

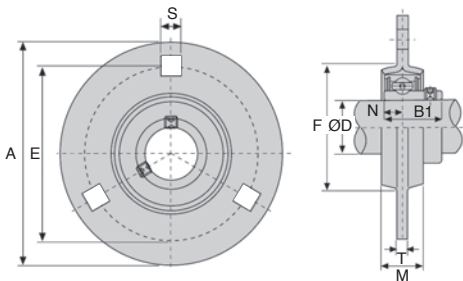

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	T	M	S	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPF204/SS	20	90	71	2	16	9	56	M8	25	7	0,29	✓	19,50 €
BPF205/SS	25	95	76	2	18	9	60	M8	27	7,5	0,34	✓	24,32 €
BPF206/SS	30	113	90	2,6	18	11	71	M8	30	8	0,55	✓	13,79 €
BPF207/SS	35	122	100	2,6	20	11	81	M10	32	8,5	0,69	-	18,17 €

Dimensions in mm

## Our other products



M0

Worm and wheel set,  
Hardened steel



DOMI50

Domino 50 adjustable  
slide, Slide DOMILINE  
50



PRF\_PGN

Door handle for  
aluminium profile,  
Handle with lock  
suitable



ZG2

Plastic spur gear,  
Machined plastic  
(delrin)



DOMI120

Connecting kits, XY  
linking kit



BPHR

Ball transfer unit  
housed spring loaded,  
High



NCT

Square tube  
connector, Fixed  
angle



CLQassortiment

Assorted feeler strips,  
Assorted feeler strips



RAS

90° ball and socket  
joints DIN71802, Steel



M1

Worm and wheel set,  
Non hardened steel



SHA

Handwheel without  
handle, Polyamide



DPAR\_DKON

Progressive stop,  
Steel

## Complementary products



BPPss

Pressed stainless  
steel pillow block,  
Stainless steel



BPFLss

Pressed stainless  
steel flange bearing,  
Stainless steel



BPF

Sheet steel flanged  
bearing for light  
loads, Sheet steel



UCF\_SS

Stainless steel flanged  
bearing, Stainless  
steel