

Pressed stainless steel bearing for light loads

BPFSS

Flange with 3 mounting holes

- Pressed sheet steel housing
- Material: stainless steel


NEW:
stainless steel
range

Application

- Mounting a simple bearing, suitable for light loads only



stainless
steel

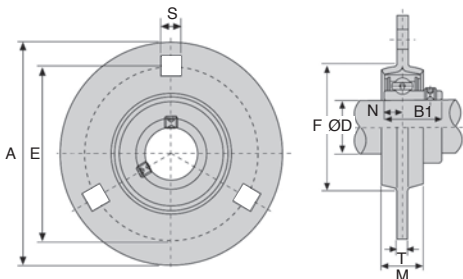

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	T	M	S	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPF204/SS	20	90	71	2	16	9	56	M8	25	7	0,29	✓	19,50 €
BPF205/SS	25	95	76	2	18	9	60	M8	27	7,5	0,34	✓	24,32 €
BPF206/SS	30	113	90	2,6	18	11	71	M8	30	8	0,55	✓	13,79 €
BPF207/SS	35	122	100	2,6	20	11	81	M10	32	8,5	0,69	-	18,17 €

Dimensions in mm

Our other products



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



BDMll

Magnetic bush for pin, Fast and light magnetic locking



BAG

Steel Clamping collar, Steel



STRIP1000

Sealing brush strip, 1m length



KKP-AR

Linear bearing with inclined ball tracks, Heavy loads / -20° +200°



GET-AL

Jaw coupling, economy range, Aluminium



PRF-SRA-78

Lock for aluminium profile, Quick fitting, self locking door lock



PSG125S

Spur gear - precision range, Stainless steel 316



gt64

Rotating bent lever, Common applications



BTC_M

End cap with threaded insert for square tube, With threaded insert



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



BLHB30

Right angled gearbox, bored shafts, up to 4.4 Nm

Complementary products



BPPss

Pressed stainless steel pillow block, Stainless steel



BPFLss

Pressed stainless steel flange bearing, Stainless steel



BPF

Sheet steel flanged bearing for light loads, Sheet steel



UCF_SS

Stainless steel flanged bearing, Stainless steel