

Pressed stainless steel bearing for light loads

BPFSS

Flange with 3 mounting holes

- Pressed sheet steel housing
- Material: stainless steel


NEW:
stainless steel
range

Application

- Mounting a simple bearing, suitable for light loads only



stainless
steel

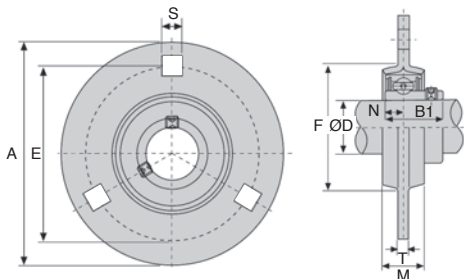

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	ØD	A	E	T	M	S	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPF204/SS	20	90	71	2	16	9	56	M8	25	7	0,29	✓	19,50 €
BPF205/SS	25	95	76	2	18	9	60	M8	27	7,5	0,34	✓	24,32 €
BPF206/SS	30	113	90	2,6	18	11	71	M8	30	8	0,55	✓	13,79 €
BPF207/SS	35	122	100	2,6	20	11	81	M10	32	8,5	0,69	-	18,17 €

Dimensions in mm

Our other products



 
NPTR_M

Adjustable cross clamp, Adjustable



T39_T49

Extension spring in metre length stainless steel, by the metre



KS

Keysteel, Steel - Keystock



PM3

Worm and wheel set, Bronze



RFK48B

Hypoid gearbox - Stainless steel, up to 350 Nm



UGCG

Actuator guide kit, Long housing



GMK17_BR

Clamp for guiding profile, Rounded only - single



MFBS

Stainless steel flexible bellows coupling, Stainless steel - with cl...



 
MRA

Quick link, Steel



NCT

Square tube connector, Fixed angle



LVTMFC

Device for controlling limit switches, For mini-actuator LVT



GP75

Spring loaded toggle latch, Standard (GP75)

Complementary products



BPPss

Pressed stainless steel pillow block, Stainless steel



BPFLss

Pressed stainless steel flange bearing, Stainless steel



BPF

Sheet steel flanged bearing for light loads, Sheet steel



UCF_SS

Stainless steel flanged bearing, Stainless steel