

# Pressed stainless steel bearing for light loads

## BPFSS

## Flange with 3 mounting holes

- Pressed sheet steel housing
- Material: stainless steel


**NEW:**  
stainless steel  
range

### Application

- Mounting a simple bearing, suitable for light loads only



stainless  
steel

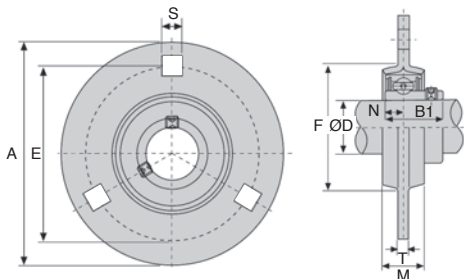

### DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List	-10%	-15%	-20%	On request

 
Part number	ØD	A	E	T	M	S	F	Bolt size	B1	N	Weight (kg)	Stock*	Price each 1 to 5
BPF204/SS	20	90	71	2	16	9	56	M8	25	7	0,29	✓	19,50 €
BPF205/SS	25	95	76	2	18	9	60	M8	27	7,5	0,34	✓	24,32 €
BPF206/SS	30	113	90	2,6	18	11	71	M8	30	8	0,55	✓	13,79 €
BPF207/SS	35	122	100	2,6	20	11	81	M10	32	8,5	0,69	-	18,17 €

Dimensions in mm

## Our other products



PRF-SMA  
Closing system for aluminium profile,  
Easily adjustable lock



B  
Steel bevel gear, 1:1



CHAupa  
Front hinge, 270°



PCS8ECO  
Chain sprocket - steel,  
8mm (DIN 05B-1)



RHTtcss  
High Temperature  
Castor, up to 200kg



MEB  
Moulded plastic bevel  
gear (nylon), 1:1



PRFSRAD  
Dual lock for  
aluminium profile,  
Quick fitting, self  
locking door du...



PTRSS  
Idler chain sprocket,  
For hostile  
environments



UCF\_PBT  
Stainless  
steel/Polymer flanged  
bearing, Polymer and



BCAss  
Stainless steel splined  
bush, Inox



BLH60  
Right angled gearbox,  
from 19 to 70 Nm



BPFL  
Sheet steel flanged  
bearing for light  
loads, Sheet steel


## Complementary products



 BPPss  
Pressed stainless  
steel pillow block,  
Stainless steel



BPFLss  
Pressed stainless  
steel flange bearing,  
Stainless steel



BPF  
Sheet steel flanged  
bearing for light  
loads, Sheet steel



UCF\_SS  
Stainless steel flanged  
bearing, Stainless  
steel