

Cylindrical flush fitting ball transfer unit

BPH


For heavy loads

- **Flush fitting ball transfer unit with flange**
- For heavy loads
- Carrying ball for handling solid body
- Machined bodies and covers
- Lubricated for life
- Orientation: horizontal with ball upwards
- Unique drainage hole
- Max. speed: 1.5m/s
- Working temperature range: -30 to +100°C
- Materials:
 - BPH:** galvanised steel body and chromed steel ball
 - BPH/AS:** galvanised steel body and 420 stainless steel balls



Advantages

- Good resistance to shocks

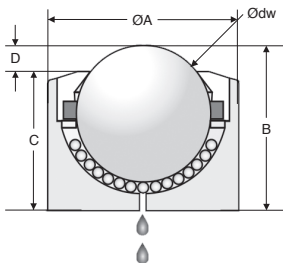

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	Net	-10%	-15%	-20%	On request

Part N°	Ødw ball	ØA	B	C	D	Carrying capacity (kg)	Weight (g)	Price each 1 to 5
Steel body, steel balls								
BPH15-24	15	24	20,0	15,0	5,0	60	0,049	7,35 €
BPH22-36	22	36	30,5	26,0	4,5	180	0,177	9,87 €
BPH30-45	30	45	36,8	30,3	6,5	350	0,335	14,33 €
BPH45-62	45	62	53,5	45,0	8,5	600	0,940	42,96 €
Steel body, stainless steel balls								
BPH15-24/AS	15	24	20,0	15,0	5,0	50	0,048	8,98 €
BPH22-36/AS	22	36	30,5	26,0	4,5	180	0,178	11,46 €
BPH30-45/AS	30	45	36,8	30,3	6,5	350	0,338	16,55 €
BPH45-62/AS	45	62	53,5	45,0	8,5	600	0,970	63,42 €

All dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



SC2

2 part rigid shaft clamp, Clamping jaw



ACL-FPA

Panel mounting block for aluminium structures, Support block



GEC

Rubber latch clamp with strike plate, Lockable



CHT71

Asynchronous AC Motor 0.18 to 0.55kW, 0.18 to 0.55kW



AC

Strike for toggle latch, 18mm



SEV

Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



M0

Worm and wheel set, Non hardened steel



TCC_SS

Stainless steel rigging screw (hook/hook), Stainless steel



SLVVlok

Vertical toggle clamp, Vertical toggle clamp / vertical foot



RFVfp

Stainless steel worm and wheel gearboxes, Mounting bracket



ADL_M

Male eye bolt conforms to DIN580, Stainless steel



ALIDR30

12 and 24V DC power supplies, 1,5 A and 2 A

Complementary products



BPH

Ball transfer unit plain fit, High



BPHT

Ball transfer unit bolt fitting, Heavy



BPHF

Ball transfer unit push fit, Heavy