

Flange mounting ball transfer unit

BPL

For light loads

- Pressed steel ball transfer unit
- With 2 fixing holes for screws or rivets
- For light loads
- Housing made from pressed sheet metal
- With drainage hole and felt seal.
- Orientation: horizontal with ball upwards
- Max. speed: 1m/s
- Working temperature range: -20 to +70°C
- Materials:

BPL:galvanised steel body and steel balls


BPL/SS:stainless steel body and stainless steel

420 balls



Advantages

- Ideal for small applications with small space requirements

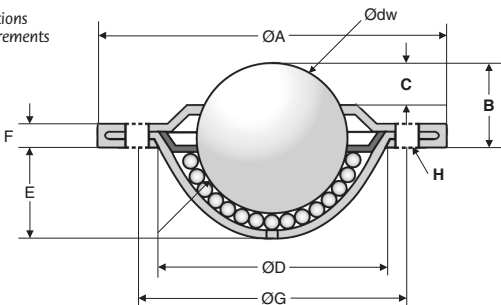

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	Net	-10%	-15%	-20%	On request

Part N°	Ødw ball	ØA	B	C	ØD	E	F	ØG	ØH	Carrying capacity (kg)	Weight (g)	Price each	Stock*	
													1 to 5	6 to 5
Corps acier / Billes acier														
BPL15-41	15,0	41,0	10,8	5,0	24,0	8,5	3,2	30,0	2 x 3,4	15	0,045	✓	4,16	€
BPL19-61	19,0	61,0	10,0	3,2	29,1	12,0	3,2	44,5	2 x 5,1	25	0,090	✓	4,05	€
BPL25-73	25,4	73,0	14,2	6,3	37,2	15,8	3,5	55,6	2 x 5,1	55	0,170	✓	5,48	€
BPL25-56	25,0	56,0	14,6	7,8	36,0	15,4	3,3	45,0	2 x 4,0	60	0,125	✓	5,87	€
BPL32-73	32,0	73,7	16,2	8,0	45,5	19,9	4,2	58,7	2 x 5,1	125	0,269	✓	9,01	€
Corps inox / Billes inox														
BPL19-61/SS	19,0	61,0	10,0	3,2	29,1	12,0	3,2	44,5	2 x 5,1	25	0,086	✓	10,20	€
BPL25-73/SS	25,4	73,0	14,2	6,3	37,2	15,8	3,5	55,6	2 x 5,1	55	0,172	-	14,75	€
BPL32-73/SS	32,0	73,7	16,2	8,0	45,5	19,9	4,2	58,7	2 x 5,1	125	0,256	✓	20,29	€

All dimensions in mm

Our other products



GET-AL
Jaw coupling,
economy range,
Aluminium



RIMple
Locking castor, with
mounting plate



JCDss
Double universal joint
- Stainless steel, Low
duty



LFM2
Steel leadscrew,
Medium carbon steel -
2 threads



BL8
Right angled gearbox,
from 0.20 to 2 Nm



UCFL
Cast iron flanged
bearing, Cast iron




CHM30-MOT
Asynchronous AC
motorgearboxes 0.09
to 0.22kW, 0.09 to
0.22kW



RURp
Swivel castor with
double brake,
Polyurethane -
Aluminium rim (Free



 BSB
Ballscrew bearing
unit, Support



CFC
Spring loaded position
switch, Electric
contact



CHMR40
Worm and wheel gear
reducer, up to 57 Nm



HLC19
Right angle spiro
bevel gearbox, Up to
43Nm

Complementary products



BPL
Ball transfer unit light
duty, Light



BPLe
Ball transfer unit push
fit, Light



BPLF
Ball transfer unit light
duty, Light