

Flange mounting ball transfer unit

BPL

For light loads

- Pressed steel ball transfer unit
- With 2 fixing holes for screws or rivets
- For light loads
- Housing made from pressed sheet metal
- With drainage hole and felt seal.
- Orientation: horizontal with ball upwards
- Max. speed: 1m/s
- Working temperature range: -20 to +70°C
- Materials:

BPL:galvanised steel body and steel balls


BPL/SS:stainless steel body and stainless steel

420 balls



Advantages

- Ideal for small applications with small space requirements

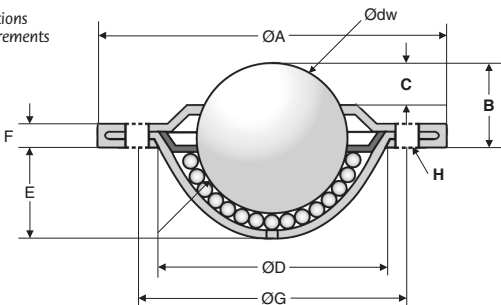

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	Net	-10%	-15%	-20%	On request

Part N°	Ødw ball	ØA	B	C	ØD	E	F	ØG	ØH	Carrying capacity (kg)	Weight (g)	Price each	Stock*	
													1 to 5	6 to 5
Corps acier / Billes acier														
BPL15-41	15,0	41,0	10,8	5,0	24,0	8,5	3,2	30,0	2 x 3,4	15	0,045	✓	4,16	€
BPL19-61	19,0	61,0	10,0	3,2	29,1	12,0	3,2	44,5	2 x 5,1	25	0,090	✓	4,05	€
BPL25-73	25,4	73,0	14,2	6,3	37,2	15,8	3,5	55,6	2 x 5,1	55	0,170	✓	5,48	€
BPL25-56	25,0	56,0	14,6	7,8	36,0	15,4	3,3	45,0	2 x 4,0	60	0,125	✓	5,87	€
BPL32-73	32,0	73,7	16,2	8,0	45,5	19,9	4,2	58,7	2 x 5,1	125	0,269	✓	9,01	€
Corps inox / Billes inox														
BPL19-61/SS	19,0	61,0	10,0	3,2	29,1	12,0	3,2	44,5	2 x 5,1	25	0,086	✓	10,20	€
BPL25-73/SS	25,4	73,0	14,2	6,3	37,2	15,8	3,5	55,6	2 x 5,1	55	0,172	-	14,75	€
BPL32-73/SS	32,0	73,7	16,2	8,0	45,5	19,9	4,2	58,7	2 x 5,1	125	0,256	✓	20,29	€

All dimensions in mm

Our other products



Q6

Deep groove ball bearing, Steel



AC

Strike for toggle latch, 15mm



 
MC

Self-compensating shock-absorber, Self-compensating - without adjust...



BABss

303 Stainless steel ball pin, 303 Stainless steel



G1

Steel spur gear, Steel 20NC22



B3PAN

Panamech, Multi-Beam stainless steel, Stainless steel - with clampin...



D19 D29

Compression springs in metre length steel, by the metre



CLM

Male clevis end, Stainless steel short



VBFP

Small 6 lobe threaded handle - female, Duroplast - Stainless



ESCON

Speed controller 5A, 5 A



CHAupa

Front hinge, 270°



GMK17_R

Round guide, Round guide for conical profile

Complementary products



BPL

Ball transfer unit light duty, Light



BPLE

Ball transfer unit push fit, Light



BPLF

Ball transfer unit light duty, Light