

High profile ball transfer unit


BPLF

For light loads

- **Pressed steel ball transfer unit with mounting plate**
- With 2 or 4 mounting holes for screws or rivets.
(The BPLF25-55-2F has 2 slots rather than 2 holes to accommodate different centre distances)
- For light loads
- Housing made from pressed steel
- With drainage hole and felt seal.
- Orientation: horizontal with ball upwards
- Max. speed: 1m/s
- Working temperature range: -20 to +70°C
- Materials:



BPL:galvanised steel body and steel balls
BPL/SS:stainless steel body and stainless steel
 420 balls

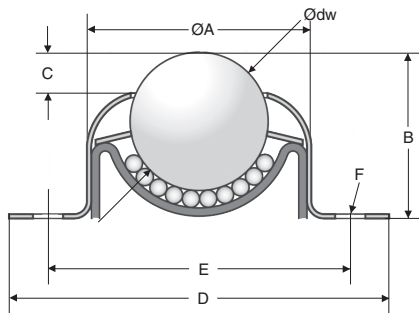

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc. Prix	-10%	-15%	-20%	On request	


Part N°	Ødw ball	ØA	B	C	D	E	F	Carrying capacity (kg)	Weight (kg)	Stock*	Price each 1 to 5
Steel body, steel balls											
BPLF25-45-2F	25,4	45,0	30,4	6,3	69 x 51	55,9 - 60,3	Fente 2 x 5,5 x 7,7	55	0,155	✓	5,84 €
BPLF38-67-4	38,1	66,9	46,2	9,8	76,2 x 76,2	62,7 x 62,7	4 x Ø7,1	115	0,520	-	17,65 €
Stainless steel body / Stainless steel ball											
BPLF25-45-2F/SS	25,4	45,0	30,4	6,3	69 x 51	55,9 - 60,3	Fente 2 x 5,5 x 7,7	55	0,151	✓	15,21 €

*Depending on availability - Dimensions in mm


Our other products



 SLB
Indexing plunger,
steel class 5.8



AC
Strike for toggle latch,
15mm

 

BH02
Single housed bearing
assembly, Bearing
secured with circlips



PTKFss
Cap nut for foot
for the food industry,
Stainless steel blind
nut - ...



BABPass
Hardened stainless
steel ball pin with
ring, With grip ring



HBM
Adjustment bushing
for half-rail guide,
Adjustment bushing



COA-COG
Surface mounting
plate, Surface
mounting plate for
ball joint



SLHVlok
Horizontal toggle
clamp, Horizontal
toggle clamp / vertical
foot



CHMBR
Reaction arm, CHM
and CHMR gear
reducers reaction arm



PRF_FIX_STD
Fastener for
aluminium profile,
Standard fastener



GGB
Female wing knob,
With blind thread



RFVcap
Stainless steel
protective cover,
Closed protective
cover

Complementary products



BPL
Ball transfer unit light
duty, Light



BPLE
Ball transfer unit push
fit, Light



BPLF
Ball transfer unit light
duty, Light